


VEE**-I...

4枚刃、荒～仕上げ加工用、不等分割

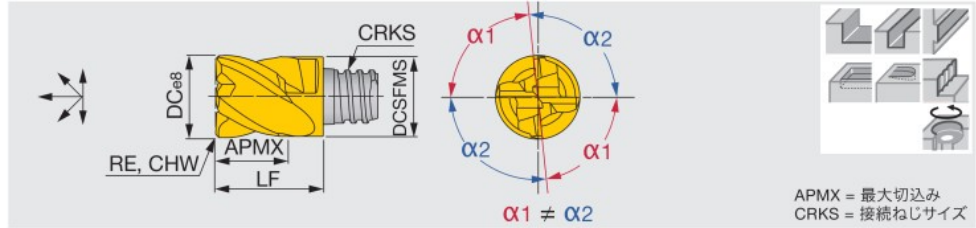


形番	AH715	AH725	NOF	FHA	DC	DCSFMS	APMX	RE	CHW	CRKS	LF	スパナ	トルク*
VEE080L05.0C30I04S05		●	4	38°	8	7.7	5	-	0.3	S05	10	KEYV-S05	7
VEE100L07.0C40I04S06		●	4	38°	10	9.7	7	-	0.4	S06	13	KEYV-S06	10
VEE120L09.0C50I04S08		●	4	38°	12	11.7	9	-	0.5	S08	16.5	KEYV-S08	15
VEE160L12.0C60I04S10	●	●	4	38°	16	15.3	12	-	0.6	S10	20.5	KEYV-S10	28
VEE200L15.0C60I04S12		●	4	38°	20	18.3	15	-	0.6	S12	25.5	KEYV-S12	28
VEE250L22.0C60I04S15		●	4	38°	25	23.9	22	-	0.6	S15	37	KEYV-W20	40
VEE250L22.0R00I04S15		●	4	38°	25	23.9	22	-	-	S15	37	KEYV-W20	40
VEE250L22.0R05I04S15	●	●	4	38°	25	23.9	22	0.5	-	S15	37	KEYV-W20	40
VEE250L22.0R10I04S15		●	4	38°	25	23.9	22	1	-	S15	37	KEYV-W20	40
VEE250L22.0R20I04S15		●	4	38°	25	23.9	22	2	-	S15	37	KEYV-W20	40
VEE250L22.0R30I04S15		●	4	38°	25	23.9	22	3	-	S15	37	KEYV-W20	40

*トルク：推奨締め付けトルク (N・m)
VEE080 ~ VEE200: 1ケース2個入り
VEE250: 1ケース1個入り

●: 新製品
●: 設定アイテム

VEE**-03...

3枚刃、荒～仕上げ加工用、汎用、キー溝加工用

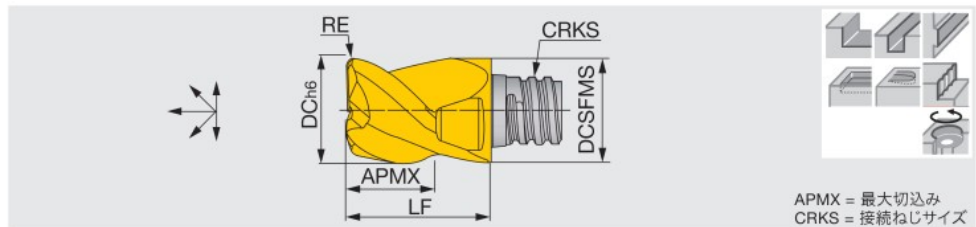

形番	AH715	AH725	NOF	FHA	DC	DCSFMS	APMX	RE	CHW	CRKS	LF	スパナ	トルク*
VEE077L04.0R02-03S05		●	3	38°	7.7	7.7	4	0.2	-	S05	10	KEYV-S05	7
VEE080L05.0R00-03S05		●	3	45°	8	7.7	5	-	-	S05	10	KEYV-S05	7
VEE097L05.0R03-03S06		●	3	38°	9.7	9.7	5	0.3	-	S06	13	KEYV-S06	10
VEE100L07.0R00-03S06		●	3	45°	10	9.7	7	-	-	S06	13	KEYV-S06	10
VEE117L07.0R03-03S08	●	●	3	38°	11.7	11.7	7	0.3	-	S08	16.5	KEYV-S08	15
VEE120L09.0R00-03S08		●	3	45°	12	11.7	9	-	-	S08	16.5	KEYV-S08	15
VEE157L08.0R03-03S10	●	●	3	38°	15.7	15.3	8	0.3	-	S10	20.5	KEYV-S10	28
VEE197L12.0R04-03S12		●	3	38°	19.7	18.3	12	0.4	-	S12	25.5	KEYV-S12	28

*トルク：推奨締め付けトルク (N・m)
1 ケース 2 個入り

●: 新製品
●: 設定アイテム