


インサート

LMMU11/16-MJ

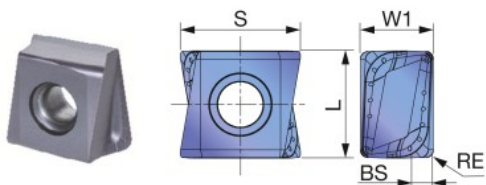

P	銅	★	☆			☆
M	ステンレス	★		☆		
K	鋳鉄		★		☆	
N	非鉄金属					
S	難削材	☆	★	☆		
H	高硬度材	★				

★：第一選択
☆：第二選択

形番	RE	APMX	コーティング						S	L	W1	BS
			AH3135	AH725	AH120	AH140	T1215	T3225				
LMMU110708PNER-MJ	0.8	9.7	●	●	●	●	●	●	11.7	10.5	7.1	2
LMMU110716PNER-MJ	1.6	9.7	●	●	●	●	●	●	11.5	10.5	7.1	1.2
LMMU110724PNER-MJ	2.4	9.7		●	●	●			11.3	10.5	7.1	0.4
LMMU110732PNER-MJ	3.2	9.7		●	●	●			11.1	10.5	7.1	-
LMMU160908PNER-MJ	0.8	15.1	●	●	●	●	●	●	17.3	16	9.5	2.4
LMMU160916PNER-MJ	1.6	15.1	●	●	●	●			17.1	16	9.5	1.6
LMMU160924PNER-MJ	2.4	15.1		●	●	●			16.9	16	9.5	0.8
LMMU160932PNER-MJ	3.2	15.1		●	●	●			16.8	16	9.5	-

●：新製品
●：設定アイテム