


2枚刃リブ加工用エンドミル、ねじれ角30°、HRC55までの高硬度鋼に対応

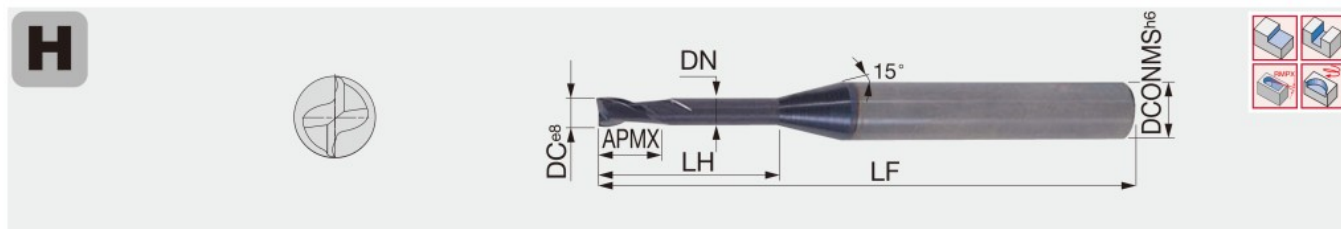

形番	AH750	DC	DCONMS	DN	APMX	LH	LF	シャンク
TEC004A2-006/02C4M45	●	0.4	4	0.37	0.6	2	45	円筒
TEC004A2-006/04C4M45	●	0.4	4	0.37	0.6	4	45	円筒
TEC005A2-007/02C4M45	●	0.5	4	0.45	0.7	2	45	円筒
TEC005A2-007/04C4M45	●	0.5	4	0.45	0.7	4	45	円筒
TEC005A2-007/06C4M45	●	0.5	4	0.45	0.7	6	45	円筒
TEC006A2-009/02C4M45	●	0.6	4	0.55	0.9	2	45	円筒
TEC006A2-009/04C4M45	●	0.6	4	0.55	0.9	4	45	円筒
TEC006A2-009/06C4M45	●	0.6	4	0.55	0.9	6	45	円筒
TEC007A2-010/02C4M45	●	0.7	4	0.65	1	2	45	円筒
TEC008A2-012/04C4M45	●	0.8	4	0.75	1.2	4	45	円筒
TEC008A2-012/06C4M45	●	0.8	4	0.75	1.2	6	45	円筒
TEC008A2-012/08C4M45	●	0.8	4	0.75	1.2	8	45	円筒
TEC009A2-0135/06C4M45	●	0.9	4	0.85	1.35	6	45	円筒
TEC009A2-0135/08C4M45	●	0.9	4	0.85	1.35	8	45	円筒
TEC009A2-0135/10C4M45	●	0.9	4	0.85	1.35	10	45	円筒
TEC010A2-015/04C4M45	●	1	4	0.97	1.5	4	45	円筒
TEC010A2-015/06C4M45	●	1	4	0.97	1.5	6	45	円筒
TEC010A2-015/08C4M45	●	1	4	0.95	1.5	8	45	円筒
TEC010A2-015/10C4M45	●	1	4	0.95	1.5	10	45	円筒
TEC010A2-015/12C4M45	●	1	4	0.93	1.5	12	45	円筒
TEC010A2-015/16C4M50	●	1	4	0.93	1.5	16	50	円筒
TEC012A2-018/06C4M45	●	1.2	4	1.17	1.8	6	45	円筒
TEC012A2-018/08C4M45	●	1.2	4	1.15	1.8	8	45	円筒
TEC012A2-018/10C4M45	●	1.2	4	1.15	1.8	10	45	円筒
TEC012A2-018/16C4M50	●	1.2	4	1.13	1.8	16	50	円筒
TEC014A2-021/06C4M45	●	1.4	4	1.35	2.1	6	45	円筒
TEC014A2-021/08C4M45	●	1.4	4	1.35	2.1	8	45	円筒
TEC014A2-021/10C4M45	●	1.4	4	1.35	2.1	10	45	円筒
TEC015A2-023/06C4M45	●	1.5	4	1.47	2.3	6	45	円筒
TEC015A2-023/08C4M45	●	1.5	4	1.45	2.3	8	45	円筒
TEC015A2-023/10C4M45	●	1.5	4	1.45	2.3	10	45	円筒
TEC015A2-023/12C4M45	●	1.5	4	1.43	2.3	12	45	円筒
TEC015A2-023/16C4M50	●	1.5	4	1.41	2.3	16	50	円筒