

インサート ネガティブタイプ


- : 連続加工
- : 弱連続加工
- ✱: 強連続加工

CN



ひし形穴つき
80°

	P	M	K	N	S	H
鋼	●	○	○	○	○	○
ステンレス	○	●	○	○	○	○
鋳鉄	○	○	●	○	○	○
非鉄金属	○	○	○	●	○	○
難削材	○	○	○	○	○	○
高硬度材	○	○	○	○	○	○

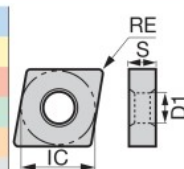

用途	プレカ記号	形番	コーティング									コートッドサーメット		サーメット		超硬	寸法 (mm)				
			T9205	T9215	T9225	T9235	T6215	T505	T515	AH8015	AH6225	AH120	GT9530	AT9530	NS9530	NS520	TH10	RE	IC	S	D1
仕上げ切削	TF	CNMG090402E-TF	●	●		●			●	●								0.2	9.525	4.76	3.81
		CNMG090404E-TF	●	●		●			●	●								0.4	9.525	4.76	3.81
		CNMG090408E-TF	●	●		●			●	●								0.8	9.525	4.76	3.81
		CNMG120402-TF	●	●		●			●	●								0.2	12.7	4.76	5.16
		CNMG120404-TF	●	●		●			●	●						●		0.4	12.7	4.76	5.16
		CNMG120408-TF	●	●		●			●	●								0.8	12.7	4.76	5.16
仕上げ切削	TSF	CNMG090402E-TSF	●	●		●			●	●		●						0.2	9.525	4.76	3.81
		CNMG090404E-TSF	●	●		●			●	●		●	●					0.4	9.525	4.76	3.81
		CNMG090408E-TSF	●	●		●			●	●		●	●					0.8	9.525	4.76	3.81
		CNMG120402-TSF	●	●		●			●	●								0.2	12.7	4.76	5.16
		CNMG120404-TSF	●	●		●			●	●		●	●					0.4	12.7	4.76	5.16
		CNMG120408-TSF	●	●		●			●	●		●	●					0.8	12.7	4.76	5.16
仕上げ切削	PS	CNMG090402E-PS	●	●		●			●	●								0.2	9.525	4.76	3.81
		CNMG090404E-PS	●	●		●			●	●								0.4	9.525	4.76	3.81
		CNMG090408E-PS	●	●		●			●	●								0.8	9.525	4.76	3.81
		CNMG120402-PS	●	●		●			●	●								0.2	12.7	4.76	5.16
		CNMG120404-PS	●	●		●			●	●								0.4	12.7	4.76	5.16
		CNMG120408-PS	●	●		●			●	●								0.8	12.7	4.76	5.16
仕上げ切削・軟鋼用	ZF	CNMG090402E-ZF	●	●		●			●	●								0.2	9.525	4.76	3.81
		CNMG090404E-ZF	●	●		●			●	●								0.4	9.525	4.76	3.81
		CNMG090408E-ZF	●	●		●			●	●								0.8	9.525	4.76	3.81
		CNMG120402-ZF	●	●		●			●	●								0.2	12.7	4.76	5.16
		CNMG120404-ZF	●	●		●			●	●		●	●					0.4	12.7	4.76	5.16
		CNMG120408-ZF	●	●		●			●	●		●	●					0.8	12.7	4.76	5.16
仕上げ切削	AS	CNMG120404-AS	●	●		●												0.4	12.7	4.76	5.16
		CNMG120408-AS	●	●		●												0.8	12.7	4.76	5.16
		CNMG120412-AS	●	●		●												1.2	12.7	4.76	5.16
仕上げ切削	NS	CNMG120404-NS																0.4	12.7	4.76	5.16
		CNMG120408-NS	●	●														0.8	12.7	4.76	5.16
仕上げ切削	TS	CNMG090402E-TS	●	●		●			●	●		●						0.2	9.525	4.76	3.81
		CNMG090404E-TS	●	●		●			●	●		●						0.4	9.525	4.76	3.81
		CNMG090408E-TS	●	●		●			●	●		●						0.8	9.525	4.76	3.81
		CNMG120402-TS	●	●		●			●	●								0.2	12.7	4.76	5.16
		CNMG120404-TS	●	●		●			●	●		●	●					0.4	12.7	4.76	5.16
		CNMG120408-TS	●	●		●			●	●		●	●					0.8	12.7	4.76	5.16
		CNMG120412-TS	●	●		●			●	●							1.2	12.7	4.76	5.16	

●: 設定アイテム

参照ページ: 外径ホルダ → C015 - 内径ホルダ → D025 - J series ホルダ → G050
TungCap → K008 - PINZBOHR® → K178 - カートリッジ → K181 -