

インサート ネガティブタイプ


- : 連続加工
- ◐ : 弱連続加工
- ✳ : 強連続加工

SN



正方形穴つき

	P	M	K	N	S	H
鋼	●	◐	◐	◐	◐	◐
ステンレス	◐	●	◐	◐	◐	◐
鋳鉄	◐	◐	●	◐	◐	◐
非鉄金属	◐	◐	◐	●	◐	◐
難削材	◐	◐	◐	◐	●	◐
高硬度材	◐	◐	◐	◐	◐	●

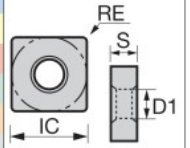

用途	プレカ記号	形番	コーティング											サーマット		超硬		寸法 (mm)										
			T9205	T9215	T9225	T9235	T6215	T5105	T5115	AH8005	AH8015	AH6225	AH6235	GH330	GT9530	AT9530	NS9530	NS520	TH10	RE	IC	S	D1					
<p>10°</p>	TS	SNMG120402-TS	●	●	●	●				●	●						●				0.2	12.7	4.76	5.16				
		SNMG120404-TS	●	●	●	●				●	●				●	●		●				0.4	12.7	4.76	5.16			
		SNMG120408-TS	●	●	●	●				●	●				●	●		●				0.8	12.7	4.76	5.16			
		SNMG120412-TS	●	●	●	●				●	●							●				1.2	12.7	4.76	5.16			
		SNMG120404-SF				●						●											0.4	12.7	4.76	5.16		
<p>78°</p>	SF	SNMG120408-SF				●				●											0.8	12.7	4.76	5.16				
SNMG120404-SS					●						●	●	●									0.4	12.7	4.76	5.16			
	SS	SNMG120408-SS				●					●	●	●								0.8	12.7	4.76	5.16				
SNMG120412-SS					●						●	●										1.2	12.7	4.76	5.16			
SNMG120408-HRF											●	●										0.8	12.7	4.76	5.16			
<p>20°</p>	HRF	SNMG120412-HRF								●	●										1.2	12.7	4.76	5.16				
<p>20°</p>		CF	SNMG120408-CF							●	●										0.8	12.7	4.76	5.16				
	SNMG120412-CF								●	●												1.2	12.7	4.76	5.16			
<p>2°</p>	01	SNGG090302-01															●	●			0.2	9.525	3.18	3.81				
		SNGG090304-01																	●	●			0.4	9.525	3.18	3.81		
		SNGG090308-01																		●	●			0.8	9.525	3.18	3.81	
		SNGG120402-01																			●	●			0.2	12.7	4.76	5.16
		SNGG120404-01																			●	●			0.4	12.7	4.76	5.16
<p>72°</p>	01	SNGG120408-01																		●	●			0.8	12.7	4.76	5.16	
SNMG120404-11																						0.4	12.7	4.76	5.16			
	11	SNMG120408-11																				0.8	12.7	4.76	5.16			

● : 設定アイテム

参照ページ： 外径ホルダ → C101 - 内径ホルダ → D043 - カートリッジ → K181 -