
 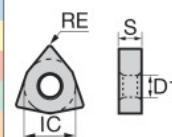


WN



ネガティブタイプ

[illegible]

用途	ブレーカ 記号	形 番	コーティング								コートデッド サーメット		サーメット		寸法 (mm)					
			T9215	T9225	T9235	T6215	AH8005	AH8015	AH6225	AH6235	AH120	GH330	GT9530	AT9530	NS9530	NS520	RE	IC	S	D1
 	TS	WNUMG060402E-TS	●	●		●		●	●				●		●		0.2	9.525	4.76	3.81
		WNUMG060404E-TS	●	●		●		●	●				●		●		0.4	9.525	4.76	3.81
		WNUMG060408E-TS	●	●		●		●	●				●		●		0.8	9.525	4.76	3.81
		WNUMG080402-TS	●	●		●		●	●						●		0.2	12.7	4.76	5.16
		WNUMG080404-TS	●	●	●	●		●	●			●	●	●	●	●	0.4	12.7	4.76	5.16
		WNUMG080408-TS	●	●	●	●		●	●			●	●	●	●	●	0.8	12.7	4.76	5.16
		WNUMG080412-TS	●	●	●	●		●	●					●			1.2	12.7	4.76	5.16
 	SF	WNUMG060404-SF				●		●									0.4	9.525	4.76	3.81
		WNUMG060408-SF				●		●									0.8	9.525	4.76	3.81
		WNUMG080404-SF				●		●									0.4	12.7	4.76	5.16
		WNUMG080408-SF				●		●									0.8	12.7	4.76	5.16
 	SS	WNUMG060404E-SS						●	●								0.4	9.525	4.76	3.81
		WNUMG060408E-SS						●	●								0.8	9.525	4.76	3.81
		WNUMG060412E-SS						●	●								1.2	9.525	4.76	3.81
		WNUMG080404-SS				●		●	●	●	●						0.4	12.7	4.76	5.16
		WNUMG080408-SS				●		●	●	●	●						0.8	12.7	4.76	5.16
		WNUMG080412-SS				●		●	●								1.2	12.7	4.76	5.16
 	HRF	WNUMG080404-HRF					●	●									0.4	12.7	4.76	5.16
		WNUMG080408-HRF					●	●									0.8	12.7	4.76	5.16

切りくず処理範囲

P

切り込み: a_p (mm)






送り: f (mm/rev)

TH

TM

TF

TSF

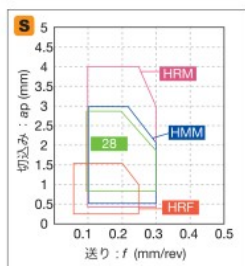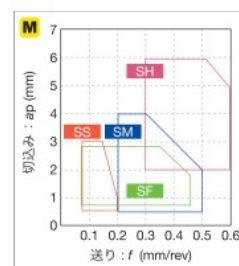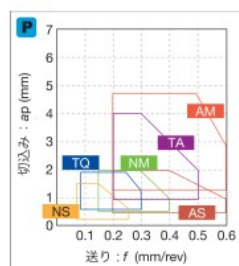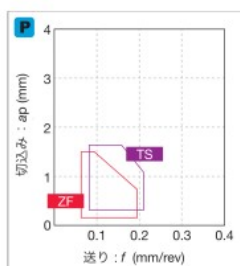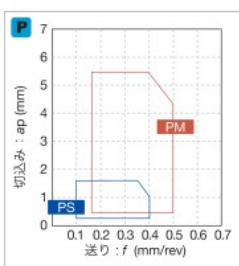

材種 インサート 外管用ホルダ 内管用ホルダ ねじ切り工具 突切り溝入れ 小型旋盤用工具 フライス工具 エンドミル

穴あけ工具 ツーリングシステム ユーザガイド 索引