



■ インサート

New


LQMU11-PXER-MJ (汎用ブレーカ)

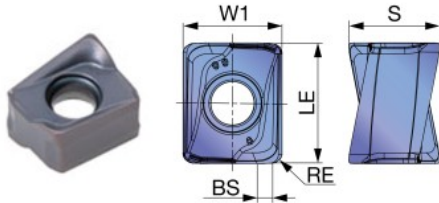


LQMU11-PXER-ML (低抵抗ブレーカ)

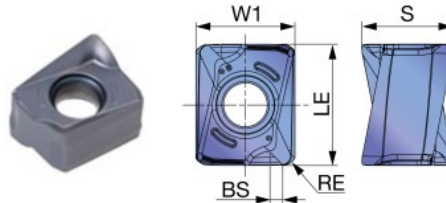

LQMU11/18-PNER-MJ (汎用ブレーカ)

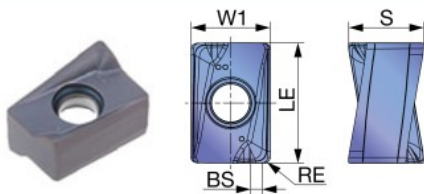

LQMU18-PNER-ML (低抵抗ブレーカ)

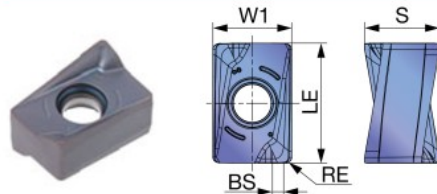

P	鋼	★	☆					☆
M	ステンレス	☆	★					☆
K	鋳鉄			★	☆	☆		
N	非鉄金属							
S	難削材		☆	★		☆		☆
H	高硬度材			★				☆

★：第一選択
☆：第二選択

形番	RE	APMX	コーティング							LE	S	W1	BS
			AH3225	AH3135	AH8015	T1215	AH120	AH140	AH725				
New LQMU110704PXER-MJ	0.4	9	★	★	★					11	8.4	9	1.5
LQMU110704PNER-MJ	0.4	9					●	●	●	11	8.4	9	1.5
LQMU110708PXER-MJ	0.8	9	●	●	●	●	●			11	8.3	9	1.1
LQMU110708PNER-MJ	0.8	9					●	●	●	11	8.3	9	1.1
New LQMU110716PXER-MJ	1.6	9	★		★					11	8.1	9	0.3
LQMU110716PNER-MJ	1.6	9					●	●	●	11	8.2	9	0.3
New LQMU110720PXER-MJ	2	9	★		★					11	8.1	9	-
LQMU110720PNER-MJ	2	9					●			11	8.1	9	-
New LQMU110704PXER-ML	0.4	9	★	★	★					11	8.4	9	1.5
New LQMU110708PXER-ML	0.8	9	●	●	●	●				11	8.3	9	1.1
LQMU180804PNER-MJ	0.4	16	●	●	●		●	●	●	17.5	10.9	11.5	2
LQMU180808PNER-MJ	0.8	16	●	●	●	●	●	●	●	17.5	10.9	11.5	1.6
LQMU180816PNER-MJ	1.6	16	●		●		●	●	●	17.5	10.9	11.5	0.8
LQMU180824PNER-MJ	2.4	16					●	●	●	17.5	10.7	11.5	-
LQMU180804PNER-ML	0.4	16	●	●	●					17.5	10.9	11.5	2
LQMU180808PNER-ML	0.8	16	●	●	●	●				17.5	10.9	11.5	1.6

●：新製品
★：2024年8月発売
●：設定アイテム