


モジュラーボディ

New

TID-L-A-M

面取り刃付きボディ TungFlexコネクション

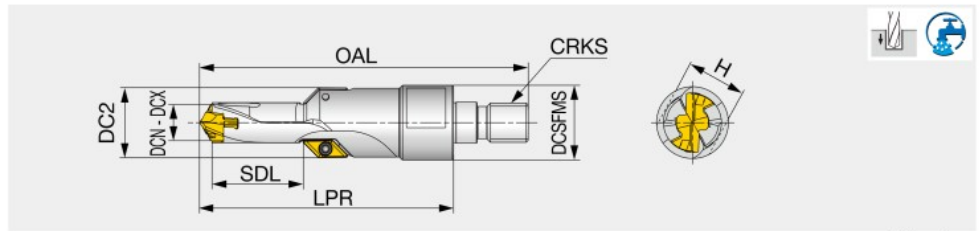

形番	DCX	DCN	DC2	SDL	DCSFMS	LPR	OAL	CRKS	H	ポケットサイズ
TID065L25A90M08	6.9	6.5	13.84	24.91	15.5	58.18	75.18	M8	10	6.5
TID085L25A90M08	8.9	8.5	15.84	25	15.5	58.29	75.29	M8	10	8
TID100L25A90M10	10.4	10	17.34	25	19	64.47	83.47	M10	15	10
TID105L25A90M10	10.9	10.5	17.84	25	19	64.56	83.56	M10	15	10
TID120L25A90M10	12.4	12	19.34	25	19	64.82	83.82	M10	15	12
TID120L40A90M10	12.4	12	19.34	40	19	79.82	98.82	M10	15	12
TID125L25A90M10	12.9	12.5	19.84	25	19	64.91	83.91	M10	15	12
TID125L40A90M10	12.9	12.5	19.84	40	19	79.91	98.91	M10	15	12
TID140L25A90M12	14.4	14	21.34	25	23.5	70.12	92.12	M12	17	14
TID140L40A90M12	14.4	14	21.34	40	23.5	85.12	107.12	M12	17	14
TID145L25A90M12	14.9	14.5	21.84	25	23.5	70.21	92.21	M12	17	14
TID145L40A90M12	14.9	14.5	21.84	40	23.5	85.21	107.21	M12	17	14
TID150L25A90M12	15.9	15	22.34	25	23.5	70.27	92.27	M12	17	15
TID150L40A90M12	15.9	15	22.34	40	23.5	85.27	107.27	M12	17	15
TID160L25A90M12	16.9	16	23.34	25	23.5	70.42	92.42	M12	17	16
TID160L40A90M12	16.9	16	23.34	40	23.5	85.42	107.42	M12	17	16


工具径	加工穴径公差の目安
φ6.5 - φ16.9	+0.04 / 0

部品

形番	クランプキー	スパナ	締付けねじ
TID065L... - TID085L...	K-TID6-9.99	T-7D	SR 34-508
TID100L... - TID160L...	K-TID10-19.99	T-7D	SR 34-508

特殊面取りホルダ用インサート

AOMT...

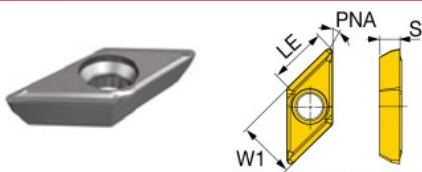

形番	LE	面取り角 PNA	コーティング			W1	S
			GH730				
AOMT060204-C45	4.5	45°	●			5.66	1.96

★：第一選択
☆：第二選択

●：設定アイテム