


# TPAV12

ねじ止め式直角肩加工用カッタ、ポアタイプ

GAMP = +6°~ +7.6°, GAMF = -37.1°~ -32.4°

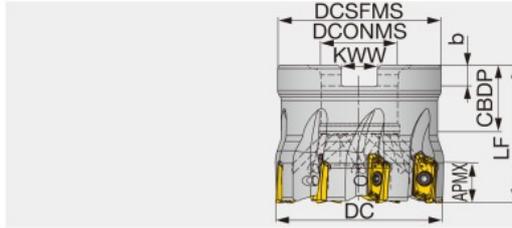

形番	APMX	DC	CICT	DCSFMS	DCONMS	CBDP	LF	KWW	b	WT(kg)	エア穴	インサート
TPAV12M050B22.0R08	11.5	50	8	47	22	20	40	10.4	6.3	0.37	あり	AVM/GT12...
TPAV12M050B22.0R12	11.5	50	12	47	22	20	40	10.4	6.3	0.37	あり	AVM/GT12...
TPAV12M063B22.0R08	11.5	63	8	47	22	20	40	10.4	6.3	0.52	あり	AVM/GT12...
TPAV12M063B22.0R14	11.5	63	14	47	22	20	40	10.4	6.3	0.54	あり	AVM/GT12...

## 部品




形番	締付けねじ	スパナ	カッタ締付ボルト
TPAV12M...	CSPB-2.5	IP-8D	CM10x30H


※ 推奨締付けトルク (N-m): CSPB-2.5, CSPB-2.5S = 1.3

## インサート

### AVMT-MM

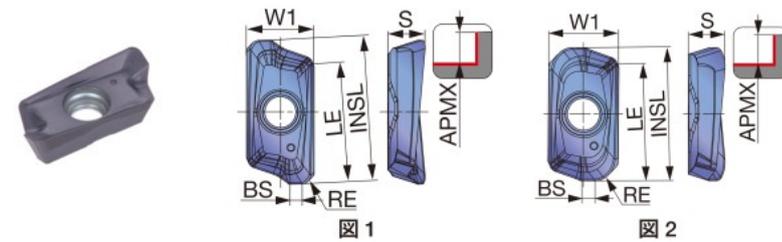

### AVGT-AM

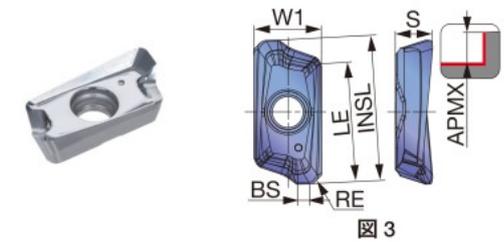

P	鋼	★	☆																	
M	ステンレス	★	☆																	
K	鋳鉄	★	☆																	
N	非鉄金属				★															
S	難削材	★	★																	
H	高硬度材	★																		

★: 第一選択  
☆: 第二選択

形番	RE	APMX	コーティング					W1	INSL	S	BS	LE	図
			AH120	AH3225	T1215	T3225	KS05F						
AVMT120404PDER-MM	0.4	11.5	●	●	●	●		6.6	14.2	3.6	1.5	11.8	1
AVMT120408PDER-MM	0.8	11.5	●	●	●	●		6.6	14.2	3.6	1.1	11.8	1
AVMT120412PDER-MM	1.2	11.5	●	●	●	●		6.6	14.2	3.6	0.7	11.8	1
AVMT120416PDER-MM	1.6	11.5	●	●	●	●		6.6	14.2	3.6	0.3	11.8	1
AVMT120420PDER-MM	2	10.5	●	●	●	●		6.6	12.7	3.4	1.2	11.1	2
AVMT120430PDER-MM	3	10.5	●	●	●	●		6.6	12.7	3.4	0.2	11.1	2
AVGT120404PDFR-AM	0.4	11.5					●	6.6	14.2	3.6	1.5	11.8	3
AVGT120408PDFR-AM	0.8	11.5					●	6.6	14.2	3.6	1.1	11.8	3

●: 設定アイテム