


## DMH 刃先強化型

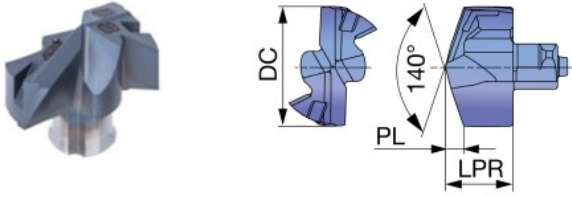

工具径	ヘッド径公差
φ6 - φ17.9	+0.018 / -0.005
φ18 - φ25.9	+0.021 / -0.005

P	鋼	★		
M	ステンレス	★		
K	鋳鉄	★		
N	非鉄金属			
S	耐熱合金	★		
H	高硬度材	★		

★：第一選択

P	鋼	★		
M	ステンレス	★		
K	鋳鉄	★		
N	非鉄金属			
S	耐熱合金	★		
H	高硬度材	★		

★：第一選択

形番	DC	LPR	コーティング		PL	ボディ
			AH9130			
DMH060	6	3.85	●		1.09	TID*060...
New DMH061	6.1	3.85	●		1.11	TID*060...
New DMH062	6.2	3.85	●		1.13	TID*060...
New DMH063	6.3	3.85	●		1.14	TID*060...
New DMH064	6.4	3.85	●		1.16	TID*060...
New DMH065	6.5	4.15	●		1.27	TID*065...
New DMH066	6.6	4.15	●		1.29	TID*065...
New DMH067	6.7	4.15	●		1.31	TID*065...
DMH068	6.8	4.15	●		1.33	TID*065...
New DMH069	6.9	4.15	●		1.34	TID*065...
DMH070	7	4.45	●		1.03	TID*070...
New DMH071	7.1	4.45	●		1.05	TID*070...
New DMH072	7.2	4.45	●		1.07	TID*070...
New DMH073	7.3	4.45	●		1.08	TID*070...
New DMH074	7.4	4.45	●		1.1	TID*070...
DMH075	7.5	4.45	●		1.12	TID*075...
New DMH076	7.6	4.45	●		1.14	TID*075...
New DMH077	7.7	4.45	●		1.16	TID*075...
New DMH078	7.8	4.45	●		1.18	TID*075...
New DMH079	7.9	4.45	●		1.19	TID*075...
DMH080	8	5.25	●		1.2	TID*080...
New DMH081	8.1	5.25	●		1.22	TID*080...
New DMH082	8.2	5.25	●		1.24	TID*080...
New DMH083	8.3	5.25	●		1.25	TID*080...
New DMH084	8.4	5.25	●		1.27	TID*080...
DMH085	8.5	5.25	●		1.29	TID*085...
DMH086	8.6	5.25	●		1.31	TID*085...
DMH087	8.7	5.25	●		1.33	TID*085...
DMH088	8.8	5.25	●		1.35	TID*085...
New DMH089	8.9	5.25	●		1.36	TID*085...
DMH090	9	5.65	●		1.37	TID*090...
New DMH091	9.1	5.65	●		1.39	TID*090...
New DMH092	9.2	5.65	●		1.41	TID*090...
New DMH093	9.3	5.65	●		1.42	TID*090...
New DMH094	9.4	5.65	●		1.44	TID*090...
DMH095	9.5	5.65	●		1.46	TID*095...
New DMH096	9.6	5.65	●		1.48	TID*095...
DMH097	9.7	5.65	●		1.5	TID*095...
New DMH098	9.8	5.65	●		1.52	TID*095...
New DMH099	9.9	5.65	●		1.53	TID*095...
DMH100	10	6.05	●		1.47	TID*100...
DMH101	10.1	6.05	●		1.49	TID*100...
New DMH102	10.2	6.05	●		1.51	TID*100...
DMH103	10.3	6.05	●		1.52	TID*100...
DMH104	10.4	6.05	●		1.54	TID*100...
DMH105	10.5	6.05	●		1.56	TID*105...
DMH106	10.6	6.05	●		1.58	TID*105...
DMH107	10.7	6.05	●		1.6	TID*105...

形番	DC	LPR	コーティング		PL	ボディ
			AH9130			
DMH108	10.8	6.05	●		1.62	TID*105...
New DMH109	10.9	6.05	●		1.63	TID*105...
DMH110	11	6.45	●		1.67	TID*110...
DMH111	11.1	6.45	●		1.69	TID*110...
DMH112	11.2	6.45	●		1.71	TID*110...
DMH113	11.3	6.45	●		1.72	TID*110...
DMH114	11.4	6.45	●		1.74	TID*110...
DMH115	11.5	6.45	●		1.76	TID*115...
New DMH116	11.6	6.45	●		1.78	TID*115...
DMH117	11.7	6.45	●		1.8	TID*115...
DMH118	11.8	6.45	●		1.82	TID*115...
New DMH119	11.9	6.45	●		1.83	TID*115...
DMH120	12	6.8	●		1.82	TID*120...
DMH121	12.1	6.8	●		1.84	TID*120...
DMH122	12.2	6.8	●		1.86	TID*120...
DMH123	12.3	6.8	●		1.87	TID*120...
DMH124	12.4	6.8	●		1.89	TID*120...
DMH125	12.5	6.8	●		1.91	TID*125...
DMH126	12.6	6.8	●		1.93	TID*125...
DMH127	12.7	6.8	●		1.95	TID*125...
DMH128	12.8	6.8	●		1.97	TID*125...
DMH129	12.9	6.8	●		1.98	TID*125...
DMH130	13	7.4	●		1.96	TID*130...
DMH131	13.1	7.4	●		1.98	TID*130...
DMH132	13.2	7.4	●		2	TID*130...
DMH133	13.3	7.4	●		2.01	TID*130...
DMH134	13.4	7.4	●		2.03	TID*130...
DMH135	13.5	7.4	●		2.05	TID*135...
DMH136	13.6	7.4	●		2.07	TID*135...
DMH137	13.7	7.4	●		2.09	TID*135...
DMH138	13.8	7.4	●		2.11	TID*135...
DMH139	13.9	7.4	●		2.12	TID*135...
DMH140	14	7.95	●		2.12	TID*140...
DMH141	14.1	7.95	●		2.14	TID*140...
DMH142	14.2	7.95	●		2.16	TID*140...
DMH143	14.3	7.95	●		2.17	TID*140...
DMH144	14.4	7.95	●		2.19	TID*140...
DMH145	14.5	7.95	●		2.21	TID*145...
DMH146	14.6	7.95	●		2.23	TID*145...
DMH147	14.7	7.95	●		2.25	TID*145...
New DMH148	14.8	7.95	●		2.27	TID*145...
New DMH149	14.9	7.95	●		2.28	TID*145...
DMH150	15	8.53	●		2.27	TID*150...
DMH151	15.1	8.53	●		2.29	TID*150...
DMH152	15.2	8.53	●		2.31	TID*150...
DMH153	15.3	8.53	●		2.32	TID*150...

φ6 - φ19.9 = 1 ケース 2 個入り  
φ20 - φ25.9 = 1 ケース 1 個入り

●：新製品  
●：設定アイテム