


**New** TCS27 (溝入れ・突切り用)

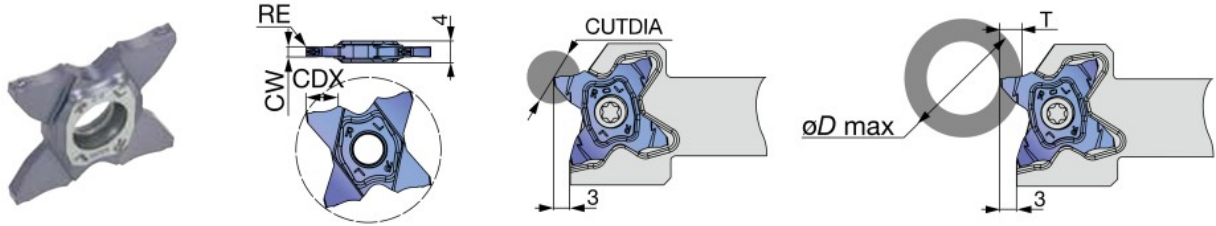

P	鋼	★	★	★
M	ステンレス	★	★	★
K	鋳鉄	★	★	★
N	非鉄金属			
S	難削材	★	★	
H	高硬度材			

★：第一選択

形番	CW±0.02	RE	コーティング			CDX	CUTDIA	溝深さ T と øD max (最大加工外径) の関係									
			AH7025	AH8005	AH6235			T ≤ 3	T ≤ 3.5	T ≤ 4	T ≤ 4.5	T ≤ 5	T ≤ 5.5	T ≤ 5.7	T ≤ 6	T ≤ 6.2	T ≤ 6.4
			●	●	●			∞	-	-	-	-	-	-	-	-	-
TCS27-075-010	0.75	0.1	●	●	●	2.5	5	∞	-	-	-	-	-	-	-	-	-
TCS27-100-006	1	0.06	●	●	●	3.5	7	∞	600	-	-	-	-	-	-	-	-
TCS27-100-010	1	0.1	●	●	●	3.5	7	∞	600	-	-	-	-	-	-	-	-
TCS27-125-010	1.25	0.1	●	●	●	3.5	7	∞	600	-	-	-	-	-	-	-	-
TCS27-125-020	1.25	0.2	●	●	●	3.5	7	∞	600	-	-	-	-	-	-	-	-
TCS27-150-010	1.5	0.1	●	●	●	5.7	11.4	∞	600	280	180	130	50	35	-	-	-
TCS27-150-020	1.5	0.2	●	●	●	5.7	11.4	∞	600	280	180	130	50	35	-	-	-
TCS27-157-015	1.57	0.15	●	●	●	3	6	∞	-	-	-	-	-	-	-	-	-
TCS27-170-010	1.7	0.1	●	●	●	3	6	∞	-	-	-	-	-	-	-	-	-
TCS27-175-010	1.75	0.1	●	●	●	3	6	∞	-	-	-	-	-	-	-	-	-
TCS27-175-020	1.75	0.2	●	●	●	3	6	∞	-	-	-	-	-	-	-	-	-
TCS27-178-018	1.78	0.18	●	●	●	3	6	∞	-	-	-	-	-	-	-	-	-
TCS27-185-020	1.85	0.2	●	●	●	3	6	∞	-	-	-	-	-	-	-	-	-
TCS27-196-015	1.96	0.15	●	●	●	3	6	∞	-	-	-	-	-	-	-	-	-
TCS27-200-010	2	0.1	●	●	●	6.4	12.8	∞	600	280	180	130	105	85	60	50	30
TCS27-200-020	2	0.2	●	●	●	6.4	12.8	∞	600	280	180	130	105	85	60	50	30
TCS27-222-015	2.22	0.15	●	●	●	3.5	7	∞	600	-	-	-	-	-	-	-	-
TCS27-230-020	2.3	0.2	●	●	●	3.5	7	∞	600	-	-	-	-	-	-	-	-
TCS27-239-015	2.39	0.15	●	●	●	5.7	11.4	∞	600	280	180	130	50	35	-	-	-
TCS27-247-020	2.47	0.2	●	●	●	5.7	11.4	∞	600	280	180	130	50	35	-	-	-
TCS27-250-010	2.5	0.1	●	●	●	5.7	11.4	∞	600	280	180	130	50	35	-	-	-
TCS27-250-030	2.5	0.3	●	●	●	5.7	11.4	∞	600	280	180	130	50	35	-	-	-
TCS27-270-010	2.7	0.1	●	●	●	6.2	12.4	∞	600	280	180	135	105	95	85	78	-
TCS27-287-020	2.87	0.2	●	●	●	6.2	12.4	∞	600	280	180	135	105	95	85	78	-
TCS27-300-020	3	0.2	●	●	●	6.4	12.8	∞	600	280	180	135	105	95	85	78	55
TCS27-300-030	3	0.3	●	●	●	6.4	12.8	∞	600	280	180	135	105	95	85	78	55
TCS27-300-040	3	0.4	●	●	●	6.4	12.8	∞	600	280	180	135	105	95	85	78	55
TCS27-315-015	3.15	0.15	●	●	●	6.4	12.8	∞	600	280	180	135	105	95	85	78	68
TCS27-318-020	3.18	0.2	●	●	●	6.4	12.8	∞	600	280	180	135	105	95	85	78	68

1 ケース 5 個入り  
●：新製品  
●：設定アイテム