


SMP 汎用ヘッド

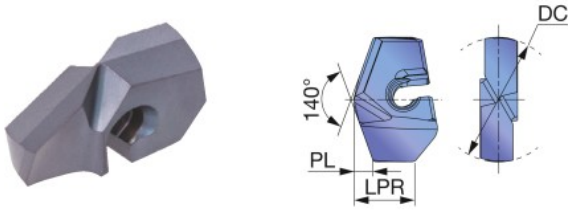

工具径	ヘッド径公差
φ20 - φ29.9	+0.014 / -0.015
φ30 - φ41	+0.014 / -0.02

P 鋼	★	★	
M ステンレス	★	★	
K 鋳鉄	★	★	
N 非鉄金属	☆	☆	
S 難削材	☆	★	
H 高硬度材	☆	★	

★: 第一選択
☆: 第二選択

P 鋼	★	★	
M ステンレス	★	★	
K 鋳鉄	★	★	
N 非鉄金属	☆	☆	
S 難削材	☆	★	
H 高硬度材	☆	★	

★: 第一選択
☆: 第二選択

形番	DC	LPR	コーティング		PL	ポケット サイズ	ボディ
			AH9130	AH725			
SMP200	20	9.65	●	●	3.11	20	TIS200F25-*
SMP201	20.1	9.61	●		3.13	20	TIS200F25-*
SMP203	20.3	9.52	●		3.16	20	TIS200F25-*
SMP205	20.5	9.44	●	●	3.2	20	TIS200F25-*
SMP206	20.6	9.4	●		3.22	20	TIS200F25-*
SMP210	21	9.23	●	●	3.29	21	TIS210F25-*
SMP213	21.3	9.1	●		3.35	21	TIS210F25-*
SMP215	21.5	9.02	●	●	3.38	21	TIS210F25-*
SMP220	22	10.54	●	●	3.42	22	TIS220F25-*
SMP222	22.2	10.46	●		3.46	22	TIS220F25-*
SMP223	22.3	10.41	●	●	3.47	22	TIS220F25-*
SMP225	22.5	10.33	●		3.51	22	TIS220F25-*
SMP230	23	10.12	●	●	3.6	23	TIS230F25-*
SMP235	23.5	9.91	●	●	3.69	23	TIS230F25-*
SMP238	23.8	9.78	●		3.75	23	TIS230F25-*
SMP240	24	10.76	●	●	3.73	24	TIS240F32-*
SMP245	24.5	10.55	●	●	3.82	24	TIS240F32-*
SMP247	24.7	10.47	●	●	3.86	24	TIS240F32-*
SMP250	25	10.34	●	●	3.91	25	TIS250F32-*
SMP255	25.5	10.13	●	●	4	25	TIS250F32-*
SMP260	26	11.55	●	●	4.04	26	TIS260F32-*
SMP261	26.1	11.51	●	●	4.06	26	TIS260F32-*
SMP262	26.2	11.47	●		4.08	26	TIS260F32-*
SMP263	26.3	11.42	●		4.09	26	TIS260F32-*
SMP264	26.4	11.38	●		4.11	26	TIS260F32-*
SMP265	26.5	11.34	●	●	4.13	26	TIS260F32-*
SMP266	26.6	11.3	●		4.15	26	TIS260F32-*
SMP267	26.7	11.26	●	●	4.17	26	TIS260F32-*
SMP270	27	11.13	●	●	4.22	27	TIS270F32-*
SMP271	27.1	11.09	●	●	4.24	27	TIS270F32-*
SMP272	27.2	11.05	●		4.26	27	TIS270F32-*
SMP273	27.3	11	●		4.28	27	TIS270F32-*
SMP275	27.5	10.92	●	●	4.31	27	TIS270F32-*
SMP276	27.6	10.88	●		4.33	27	TIS270F32-*
SMP279	27.9	10.75	●	●	4.39	27	TIS270F32-*
SMP280	28	11.74	●	●	4.35	28	TIS280F32-*
SMP281	28.1	11.7	●	●	4.37	28	TIS280F32-*
SMP283	28.3	11.61	●		4.4	28	TIS280F32-*
SMP285	28.5	11.53	●	●	4.44	28	TIS280F32-*
SMP286	28.6	11.49	●	●	4.46	28	TIS280F32-*
SMP290	29	11.32	●	●	4.53	29	TIS290F32-*
SMP291	29.1	11.28	●	●	4.55	29	TIS290F32-*
SMP293	29.3	11.19	●		4.59	29	TIS290F32-*
SMP295	29.5	11.11	●	●	4.62	29	TIS290F32-*
SMP296	29.6	11.07	●	●	4.64	29	TIS290F32-*

形番	DC	LPR	コーティング		PL	ポケット サイズ	ボディ
			AH9130	AH725			
SMP297	29.7	11.03	●		4.66	29	TIS290F32-*
SMP298	29.8	10.98	●		4.68	29	TIS290F32-*
SMP299	29.9	10.94	●		4.7	29	TIS290F32-*
SMP300	30	14.14	●	●	4.67	30	TIS300F32-*
SMP301	30.1	14.1	●	●	4.69	30	TIS300F32-*
SMP302	30.2	14.06	●	●	4.71	30	TIS300F32-*
SMP303	30.3	14.01	●		4.72	30	TIS300F32-*
SMP304	30.4	13.97	●		4.74	30	TIS300F32-*
SMP305	30.5	13.93	●	●	4.76	30	TIS300F32-*
SMP307	30.7	13.85	●		4.8	30	TIS300F32-*
SMP308	30.8	13.8	●	●	4.82	30	TIS300F32-*
SMP310	31	13.72	●	●	4.85	31	TIS310F32-*
SMP311	31.1	13.68	●		4.87	31	TIS310F32-*
SMP313	31.3	13.59	●		4.91	31	TIS310F32-*
SMP315	31.5	13.51	●	●	4.94	31	TIS310F32-*
SMP318	31.8	13.38	●		5	31	TIS310F32-*
SMP320	32	14.53	●	●	4.98	32	TIS320F40-*
SMP321	32.1	14.49	●		5	32	TIS320F40-*
SMP322	32.2	14.45	●		5.02	32	TIS320F40-*
SMP325	32.5	14.32	●	●	5.07	32	TIS320F40-*
SMP328	32.8	14.19	●	●	5.13	32	TIS320F40-*
SMP330	33	14.11	●	●	5.16	33	TIS330F40-*
SMP331	33.1	14.07	●		5.18	33	TIS330F40-*
SMP333	33.3	13.98	●		5.22	33	TIS330F40-*
SMP335	33.5	13.9	●		5.25	33	TIS330F40-*
SMP339	33.9	13.73	●		5.33	33	TIS330F40-*
SMP340	34	13.69	●	●	5.34	34	TIS340F40-*
SMP341	34.1	13.65	●		5.36	34	TIS340F40-*
SMP343	34.3	13.56	●		5.4	34	TIS340F40-*
SMP345	34.5	13.48	●	●	5.44	34	TIS340F40-*
SMP349	34.9	13.31	●		5.51	34	TIS340F40-*
SMP350	35	16.56	●	●	5.44	35	TIS350F40-*
SMP351	35.1	16.52	●		5.46	35	TIS350F40-*
SMP352	35.2	16.48	●		5.48	35	TIS350F40-*
SMP355	35.5	16.35	●	●	5.53	35	TIS350F40-*
SMP357	35.7	16.27	●		5.57	35	TIS350F40-*
SMP360	36	16.14	●	●	5.62	36	TIS360F40-*
SMP361	36.1	16.1	●	●	5.64	36	TIS360F40-*
SMP362	36.2	16.06	●		5.66	36	TIS360F40-*
SMP365	36.5	15.93	●		5.71	36	TIS360F40-*
SMP366	36.6	15.89	●		5.73	36	TIS360F40-*
SMP370	37	15.72	●		5.8	37	TIS370F40-*
SMP371	37.1	15.68	●		5.82	37	TIS370F40-*

●: 新製品
●: 設定アイテム
1ケース1個入り