





## ■ インサート


### WPMW05/06

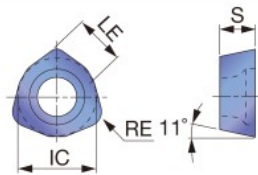


### WPMT08/09

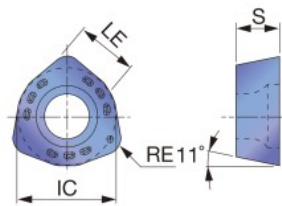


### WPMT05/06/08/09-ML

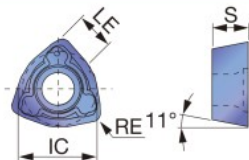

### WPMT05/06/08/09-MH

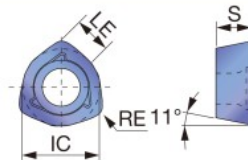

### WPMT05/06/08/09-DML

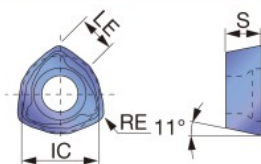

P	鋼	☆				☆	★													
M	ステンレス		★	☆						★										
K	鋳鉄	★																		
N	非鉄金属																			
S	難削材	★	☆																	
H	高硬度材					★														

★：第一選択  
 ☆：第二選択

形番	RE	APMX	コーティング						LE	IC	S
			AH120	AH130	AH140	AH730	T3130	AH3135			
WPMW05H315ZPR	1.5	1.5	●	●	●	●	●	5	7.94	3.5	
WPMT05H315ZPR-ML	1.5	1.5	●	●	●	●	●	5	7.94	3.5	
WPMT05H315ZPR-MH	1.5	1.5	●	●	●	●	●	5	7.94	3.5	
WPMT05H315ZPR-DML	1.5	1.5				●		5	7.94	3.5	
WPMW06X415ZPR	1.5	1.5	●	●	●	●	●	6	9.525	4.2	
WPMT06X415ZPR-ML	1.5	1.5	●	●	●	●	●	6	9.525	4.2	
WPMT06X415ZPR-MH	1.5	1.5	●	●	●	●	●	6	9.525	4.2	
WPMT06X415ZPR-DML	1.5	1.5				●		6	9.525	4.2	
WPMT080615ZSR	1.5	1.5	●	●	●	●	●	8	12.87	6.35	
WPMT080615ZPR-ML	1.5	1.5	●	●	●	●	●	8	12.87	6.35	
WPMT080615ZSR-MH	1.5	1.5	●	●	●	●	●	8	12.87	6.35	
WPMT080615ZPR-DML	1.5	1.5				●		8	12.87	6.35	
WPMT090725ZSR	2.5	3	●	●	●	●	●	9	15	7	
WPMT090725ZPR-ML	2.5	3	●	●	●	●	●	9	15	7	
WPMT090725ZSR-MH	2.5	3	●	●	●	●	●	9	15	7	
WPMT090725ZPR-DML	2.5	3				●		9	15	7	

●：設定アイテム