 
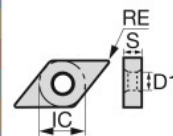
 
 


インサート ネガティブタイプ


- ：連続加工
- ◐：弱断続加工
- ✱：強断続加工

DN

[illegible]

用途	ブレーカ 記号	形 番	コーティング				寸法 (mm)							
			T6215	AH6225	AH6235					RE	IC	S	D1	
中切削		S DNMG150404R-S	●	●							0.4	12.7	4.76	5.16
		DNMG150404L-S	●	●							0.4	12.7	4.76	5.16
		DNMG150408R-S	●	●							0.8	12.7	4.76	5.16
		DNMG150408L-S	●	●							0.8	12.7	4.76	5.16
		DNMG150604R-S	●	●							0.4	12.7	6.35	5.16
		DNMG150604L-S	●	●							0.4	12.7	6.35	5.16
		DNMG150608R-S	●	●							0.8	12.7	6.35	5.16
		DNMG150608L-S	●	●							0.8	12.7	6.35	5.16
中重切削		SH DNMG150408-SH	●	●							0.8	12.7	4.76	5.16
		DNMG150412-SH	●	●							1.2	12.7	4.76	5.16
		DNMG150416-SH	●	●							1.6	12.7	4.76	5.16
		DNMG150608-SH	●	●							0.8	12.7	6.35	5.16
		DNMG150612-SH	●	●							1.2	12.7	6.35	5.16

SN

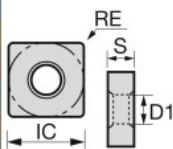[illegible]

用途	ブレーカ 記号	形 番	コーティング																寸法 (mm)			
			T6215	AH6225	AH6235															RE	IC	S
仕上げ切削	SF	SNMG120404-SF	●	●															0.4	12.7	4.76	5.16
		SNMG120408-SF	●	●															0.8	12.7	4.76	5.16
																						
																						
	SS	SNMG120404-SS	●	●	●														0.4	12.7	4.76	5.16
	SNMG120408-SS	●	●	●														0.8	12.7	4.76	5.16	
	SNMG120412-SS	●	●	●														1.2	12.7	4.76	5.16	
																						
																						

●：新製品
●：設定アイテム