

T6200 & AH6200


インサート ネガティブタイプ

- : 連続加工
- ◐ : 弱連続加工
- ✳ : 強連続加工

SN



材料	コーティング	連続加工	弱連続加工	強連続加工
P 鋼	● ● ● ●			
M ステンレス	● ● ● ●			
K 鋳鉄				
N 非鉄金属				
S 難削材				
H 高硬度材				

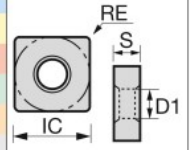

用途	ブレード記号	形番	コーティング				寸法 (mm)			
			T6215	AH6225	AH6235	RE	IC	S	D1	
中切削	SM	SNMG120408-SM	●	●	●	0.8	12.7	4.76	5.16	
		SNMG120412-SM	●	●	●	1.2	12.7	4.76	5.16	
	SDM	SNMG120408-SDM	●	●	●	0.8	12.7	4.76	5.16	
		SNMG120412-SDM	●	●	●	1.2	12.7	4.76	5.16	
	全周	SNMG150612	●			1.2	15.875	6.35	6.35	
		SNMG190612	●			1.2	19.05	6.35	7.93	
	SA	SNMG120404-SA	●	●	●	0.4	12.7	4.76	5.16	
		SNMG120408-SA	●	●	●	0.8	12.7	4.76	5.16	
	SNMG120412-SA	●	●	●	1.2	12.7	4.76	5.16		
S	SNMG120404R-S	●	●		0.4	12.7	4.76	5.16		
	SNMG120404L-S	●	●		0.4	12.7	4.76	5.16		
	SNMG120408R-S	●	●		0.8	12.7	4.76	5.16		
	SNMG120408L-S	●	●		0.8	12.7	4.76	5.16		
中〜重切削	SH	SNMG120408-SH	●	●		0.8	12.7	4.76	5.16	
		SNMG120412-SH	●	●		1.2	12.7	4.76	5.16	
		SNMG150612-SH	●	●		1.2	15.875	6.35	6.35	
		SNMG150616-SH	●	●		1.6	15.875	6.35	6.35	
		SNMG190612-SH	●	●		1.2	19.05	6.35	7.93	
		SNMG190616-SH	●	●		1.6	19.05	6.35	7.93	

- : 新製品
- : 設定アイテム