

T6200 & AH6200


インサート ポジティブタイプ

- : 連続加工
- ◐ : 弱断続加工
- ✳ : 強断続加工

CC

ひし形穴つき
80° ポジ7°

	P 鋼	M ステンレス	K 鋳鉄	N 非鉄金属	S 難削材	H 高硬度材	コーティング																
●	●	●	●	●	●	●	T6215	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
●	●	●	●	●	●	●	AH6225	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
●	●	●	●	●	●	●	AH6235	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●

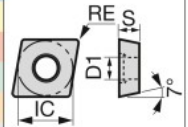


用途	ブレード 記号	形番	コーティング			寸法 (mm)			
			T6215	AH6225	AH6235	RE	IC	S	D1
中切削		PM CCMT060204-PM	●	●	●	0.4	6.35	2.38	2.8
		CCMT060208-PM	●	●	●	0.8	6.35	2.38	2.8
		CCMT09T304-PM	●	●	●	0.4	9.525	3.97	4.4
		CCMT09T308-PM	●	●	●	0.8	9.525	3.97	4.4
		CCMT09T312-PM	●	●	●	1.2	9.525	3.97	4.4
		CCMT120408-PM	●	●	●	0.8	12.7	4.76	5.5
		CCMT120412-PM	●	●	●	1.2	12.7	4.76	5.5
		24 CCMT060208-24	●			0.8	6.35	2.38	2.8
CCMT09T308-24	●			0.8	9.525	3.97	4.4		

CP

ひし形穴つき
80° ポジ11°

	P 鋼	M ステンレス	K 鋳鉄	N 非鉄金属	S 難削材	H 高硬度材	コーティング															
●	●	●	●	●	●	●	T6215	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
●	●	●	●	●	●	●	AH6225	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
●	●	●	●	●	●	●	AH6235	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●

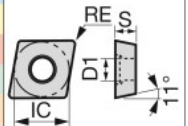

用途	ブレード 記号	形番	コーティング			寸法 (mm)			
			T6215	AH6225	AH6235	RE	IC	S	D1
仕上げ〜軽切削		PSS CPMT080204-PSS	●	●	●	0.4	7.94	2.38	3.4
		CPMT080208-PSS	●	●	●	0.8	7.94	2.38	3.4
		CPMT090304-PSS	●	●	●	0.4	9.525	3.18	4.4
		CPMT090308-PSS	●	●	●	0.8	9.525	3.18	4.4
仕上げ〜中切削		PS CPMT080202-PS	●	●	●	0.2	7.94	2.38	3.4
		CPMT080204-PS	●	●	●	0.4	7.94	2.38	3.4
		CPMT080208-PS	●	●	●	0.8	7.94	2.38	3.4
		CPMT090304-PS	●	●	●	0.4	9.525	3.18	4.4
		CPMT090308-PS	●	●	●	0.8	9.525	3.18	4.4
中切削		PM CPMT060204-PM	●	●	●	0.4	6.35	2.38	2.8
		CPMT060208-PM	●	●	●	0.8	6.35	2.38	2.8
		CPMT090304-PM	●	●	●	0.4	9.525	3.18	4.4
		CPMT090308-PM	●	●	●	0.8	9.525	3.18	4.4

- : 新製品
- : 設定アイテム