


TFMRN

耐熱合金加工用正面フライスカッタ、工具径 $\phi 63 - \phi 80$ mm

GAMP = -7° , GAMF = $+15^\circ$

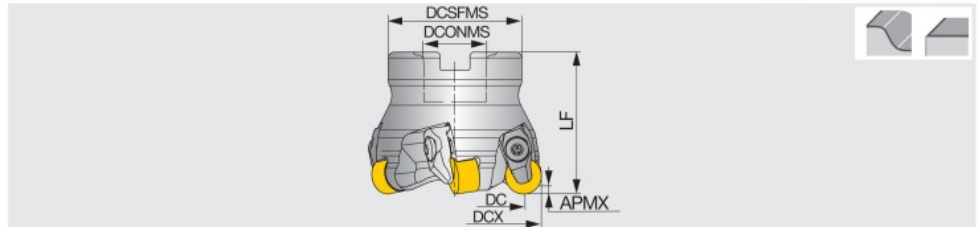


形番	APMX	DC	DCX	CICT	DCONMS	LF	DCSFMS	WT(kg)	インサート
TFMRN563-22R-12FL	2	50.35	63	5	22	50	47	0.6	RNGN120700...
TFMRN580-27R-12FL	2	67.37	80	5	27	50	58	0.9	RNGN120700...

部品	形番	押え金	締付けねじ	スナップリング
	TFMRN**-**R-12FL	CCL-5S-F	CLS3C	CSR2

インサート


RNGN120700

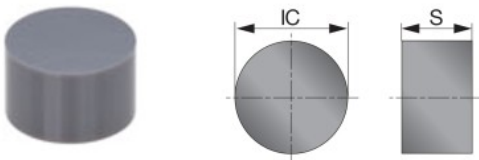

形番	APMX	刃先形状	セラミック		IC	S
			TS200	TS300		
RNGN120700-E	2	E	●		12.7	7.94
RNGN120700-T1	2	T1	●		12.7	7.94
RNGN120700-E	2	E		●	12.7	7.94
RNGN120700-T1	2	T1		●	12.7	7.94

●: 設定アイテム

 E: 低切削抵抗形



T1: 耐欠損形

