


# TS200 & TS300


TUNGALOY

## インサート


RNGN-E/T1

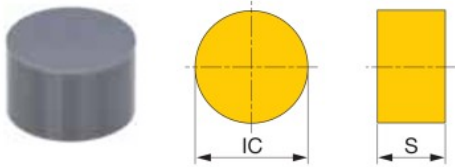


CNGN-E/T1

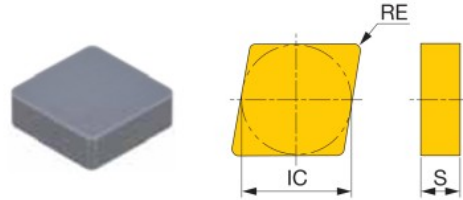

SNGN-T1

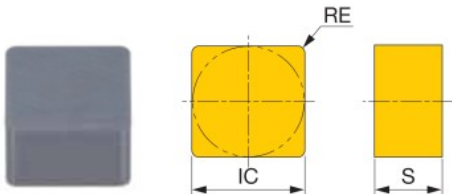

RCGX-E/T1

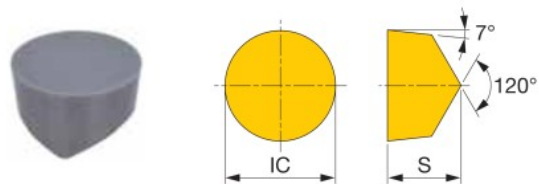


P	鋼								
M	ステンレス								
K	鋳鉄								
N	非鉄金属								
S	難削材	★	★						
H	高硬度材								

★：第一選択

形番	刃先仕様	セラミック										RE	IC	S	
		TS200	TS300												
RNGN120700-E	E	●	●										-	12.7	7.94
RNGN120700-T1	T1	●	●										-	12.7	7.94
CNGN120408-E	E		●										0.8	12.7	4.76
CNGN120412-E	E		●										1.2	12.7	4.76
CNGN120412-T1	T1	●											1.2	12.7	4.76
CNGN120708-E	E		●										0.8	12.7	7.94
CNGN120712-E	E	●	●										1.2	12.7	7.94
CNGN120716-T1	T1	●											1.6	12.7	7.94
SNGN120712-T1	T1		●										1.2	12.7	7.94
RCGX090700-E	E	●	●										-	9.525	7.94
RCGX090700-T1	T1	●	●										-	9.525	7.94
RCGX120700-E	E	●	●										-	12.7	7.94
RCGX120700-T1	T1	●	●										-	12.7	7.94

●：設定アイテム

 E：低切削抵抗形



T1：耐欠損形

