


TCS18R/L (3次元ブレーカ、ホーニング付き)

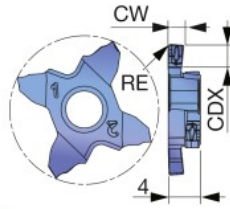

本図は右勝手 (R) を示す。

P	銅	★
M	ステンレス	★
K	鋳鉄	★
N	非鉄金属	
S	難削材	★
H	高硬度材	

★：第一選択

形番	勝手	CW±0.02	RE	コーティング							CDX
				AH7025							
TCS18R100-010	R	1	0.1	●							2
TCS18L100-010	L	1	0.1	●							2
TCS18R120-010	R	1.2	0.1	●							2
TCS18L120-010	L	1.2	0.1	●							2
TCS18R125-010	R	1.25	0.1	●							2
TCS18L125-010	L	1.25	0.1	●							2
TCS18R125-020	R	1.25	0.2	●							2
TCS18L125-020	L	1.25	0.2	●							2
TCS18R130-020	R	1.3	0.2	●							3.5
TCS18L130-020	L	1.3	0.2	●							3.5
TCS18R140-010	R	1.4	0.1	●							3.5
TCS18L140-010	L	1.4	0.1	●							3.5
TCS18R140-020	R	1.4	0.2	●							3.5
TCS18L140-020	L	1.4	0.2	●							3.5
TCS18R145-010	R	1.45	0.1	●							3.5
TCS18L145-010	L	1.45	0.1	●							3.5
TCS18R150-010	R	1.5	0.1	●							3.5
TCS18L150-010	L	1.5	0.1	●							3.5
TCS18R150-020	R	1.5	0.2	●							3.5
TCS18L150-020	L	1.5	0.2	●							3.5
TCS18R160-020	R	1.6	0.2	●							3.5
TCS18L160-020	L	1.6	0.2	●							3.5
TCS18R170-020	R	1.7	0.2	●							3.5
TCS18L170-020	L	1.7	0.2	●							3.5
TCS18R175-010	R	1.75	0.1	●							3.5
TCS18L175-010	L	1.75	0.1	●							3.5
TCS18R175-020	R	1.75	0.2	●							3.5
TCS18L175-020	L	1.75	0.2	●							3.5
TCS18R185-020	R	1.85	0.2	●							3.5
TCS18L185-020	L	1.85	0.2	●							3.5
TCS18R195-020	R	1.95	0.2	●							3.5
TCS18L195-020	L	1.95	0.2	●							3.5
TCS18R200-010	R	2	0.1	●							3.5
TCS18L200-010	L	2	0.1	●							3.5
TCS18R200-020	R	2	0.2	●							3.5
TCS18L200-020	L	2	0.2	●							3.5
TCS18R225-020	R	2.25	0.2	●							3.5
TCS18L225-020	L	2.25	0.2	●							3.5
TCS18R230-020	R	2.3	0.2	●							3.5
TCS18L230-020	L	2.3	0.2	●							3.5
TCS18R250-010	R	2.5	0.1	●							3.5
TCS18L250-010	L	2.5	0.1	●							3.5
TCS18R250-020	R	2.5	0.2	●							3.5
TCS18L250-020	L	2.5	0.2	●							3.5

1 ケース 5 個入り
 ●：新製品
 ●：設定アイテム