


MY-T SERIES

CGWSR/L-CGD

外径溝入れ、突切り用バイト

溝入れ工具

MY-T SERIES

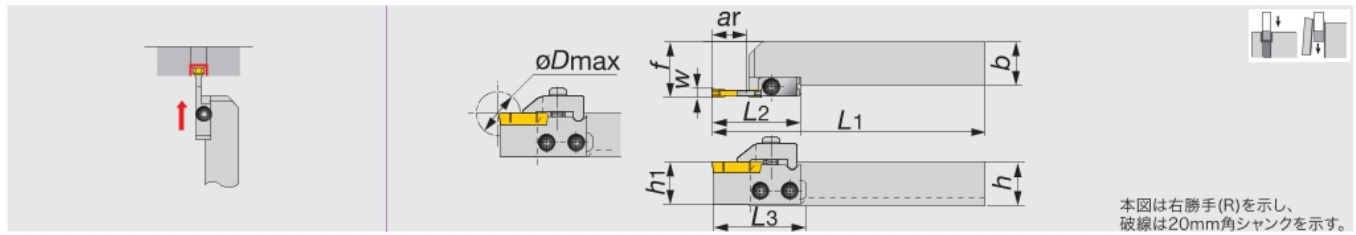

形番	W	ϕD_{max}	ar	h	b	L1	L2	L3	h1	f	インサート	シャンク	ブレード
CGWSR/L2020-CGDR/L2	2	35	16	20	20	152	45	48.5	20	26.45	CGD200	CGWSR/L2020	CGDR/L2
CGWSR/L2525-CGDR/L2	2	35	16	25	25	152	45	-	25	31.45	CGD200	CGWSR/L2525	CGDR/L2
CGWSR/L2020-CGDR/L3	3	46	21.6	20	20	157.6	50.6	54.1	20	26.45	CGD300	CGWSR/L2020	CGDR/L3
CGWSR/L2525-CGDR/L3	3	46	21.6	25	25	157.6	50.6	-	25	31.45	CGD300	CGWSR/L2525	CGDR/L3
CGWSR/L2020-CGDR/L4	4	46	21.6	20	20	157.6	50.6	54.1	20	26.65	CGD400	CGWSR/L2020	CGDR/L4
CGWSR/L2525-CGDR/L4	4	46	21.6	25	25	157.6	50.6	0	25	31.65	CGD400	CGWSR/L2525	CGDR/L4
CGWSR/L2020-CGDR/L5	5	46	21.6	20	20	157.6	50.6	54.1	20	26.95	CGD500	CGWSR/L2020	CGDR/L5
CGWSR/L2525-CGDR/L5	5	46	21.6	25	25	157.6	50.6	-	25	31.95	CGD500	CGWSR/L2525	CGDR/L5
CGWSR/L2020-CGDR/L6	6	46	21.6	20	20	157.6	50.6	54.1	20	27.1	CGD600	CGWSR/L2020	CGDR/L6
CGWSR/L2525-CGDR/L6	6	46	21.6	25	25	157.6	50.6	-	25	32.1	CGD600	CGWSR/L2525	CGDR/L6
CGWSR2525-8	7 / 8	50	21.6	25	25	150	-	-	25	26.35	CGD700, CGD800	-	-
CGWSR3232-8	7 / 8	50	21.6	32	32	170	-	-	32	33.35	CGD700, CGD800	-	-

右勝手のシャンク (CGWSR...)には右勝手のブレードセット (GGDR*)を、左勝手のシャンク (CGWSL...)には左勝手のブレードセット (CGDL*)をご使用ください。

部品

形番	ブレード	押え金	締付けねじ	ブレード止めねじ	スプリングピン	スプリング	スパナ
CGWSR****-CGDR2	TCR2	CCR2	RT-1	CSHB-6	-	BP-9	P-4
CGWSL****-CGDL2	TCL2	CCL2	RT-1	CSHB-6	-	BP-9	P-4
CGWSR****-CGDR3	TCR3	CCR3	RT-1	CSHB-6	-	BP-9	P-4
CGWSL****-CGDL3	TCL3	CCL3	RT-1	CSHB-6	-	BP-9	P-4
CGWSR****-CGDR4	TCR4	CCR4	RT-1	CSHB-6	-	BP-9	P-4
CGWSL****-CGDL4	TCL4	CCL4	RT-1	CSHB-6	-	BP-9	P-4
CGWSR****-CGDR5	TCR5	CCR5	RT-1	CSHB-6	-	BP-9	P-4
CGWSL****-CGDL5	TCL5	CCL5	RT-1	CSHB-6	-	BP-9	P-4
CGWSR****-CGDR6	TCR6	CCR6	RT-1	CSHB-6	-	BP-9	P-4
CGWSL****-CGDL6	TCL6	CCL6	RT-1	CSHB-6	-	BP-9	P-4
CGWSR****-8	-	CCR/L-8	CHHM6-20	-	5X14AW	BP-9	P-5

外径

突切り

参照ページ

インサート, 標準切削条件 → C103