


CFGSR/L-#S/D

端面溝入れ用バイト

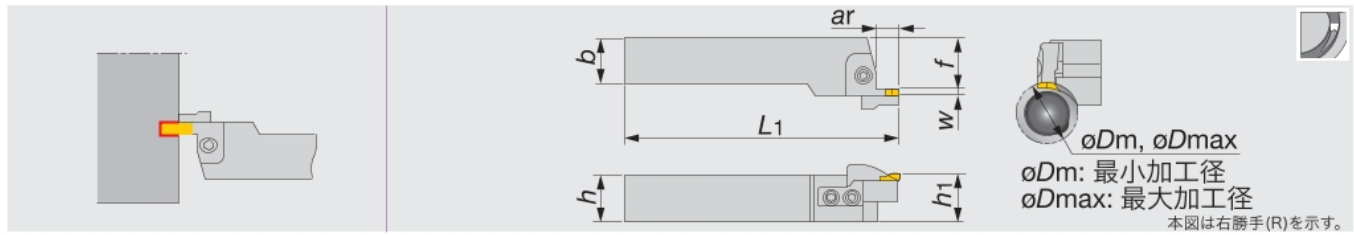

形番	W	øDm	øDmax	ar	h	b	L1	h1	f	インサート
CFGSR/L2020-3SA	3	30	40	10	20	20	125	21	22	FGC3
CFGSR/L2020-3SB	3	40	50	10	20	20	125	21	22	FGC3
CFGSR/L2020-3SC	3	50	60	10	20	20	125	21	22	FGC3
CFGSR/L2020-3SD	3	60	80	10	20	20	125	20.5	22	FGC3
CFGSR/L2020-3SE	3	80	120	10	20	20	125	20.5	22	FGC3
CFGSR/L2525-3SA	3	30	40	10	25	25	150	26	29	FGC3
CFGSR/L2525-3SB	3	40	50	10	25	25	150	26	29	FGC3
CFGSR/L2525-3SC	3	50	60	10	25	25	150	26	29	FGC3
CFGSR/L2525-3SD	3	60	80	10	25	25	150	25.5	29	FGC3
CFGSR/L2525-3SE	3	80	120	10	25	25	150	25.5	29	FGC3
CFGSR/L2020-4SA	4	30	40	10	20	20	125	21	21	FGC4
CFGSR/L2020-4SB	4	40	50	10	20	20	125	21	21	FGC4
CFGSR/L2020-4SC	4	50	60	10	20	20	125	21	21	FGC4
CFGSR/L2020-4SD	4	60	80	10	20	20	125	20.5	21	FGC4
CFGSR/L2020-4SE	4	80	120	10	20	20	125	20.5	21	FGC4
CFGSR/L2525-4SA	4	30	40	10	25	25	150	26	28	FGC4
CFGSR/L2525-4SB	4	40	50	10	25	25	150	26	28	FGC4
CFGSR/L2525-4SC	4	50	60	10	25	25	150	26	28	FGC4
CFGSR/L2525-4SD	4	60	80	10	25	25	150	25.5	28	FGC4
CFGSR/L2525-4SE	4	80	120	10	25	25	150	25.5	28	FGC4
CFGSR/L2525-4DA	4	30	40	20	25	25	160	26	28	FGC4
CFGSR/L2525-4DB	4	40	50	20	25	25	160	26	28	FGC4
CFGSR/L2525-4DC	4	50	60	20	25	25	160	26	28	FGC4
CFGSR/L2525-4DD	4	60	80	20	25	25	160	25.5	28	FGC4
CFGSR/L2525-4DE	4	80	120	20	25	25	160	25.5	28	FGC4
CFGSR/L2020-5SA	5	30	40	12	20	20	127	21	20	FGC5
CFGSR/L2020-5SB	5	40	50	12	20	20	127	21	20	FGC5
CFGSR/L2020-5SC	5	50	60	12	20	20	127	21	20	FGC5
CFGSR/L2020-5SD	5	60	80	12	20	20	127	20.5	20	FGC5
CFGSR/L2020-5SE	5	80	120	12	20	20	127	20.5	20	FGC5
CFGSR/L2525-5SA	5	30	40	12	25	25	152	26	27	FGC5
CFGSR/L2525-5SB	5	40	50	12	25	25	152	26	27	FGC5
CFGSR/L2525-5SC	5	50	60	12	25	25	152	26	27	FGC5
CFGSR/L2525-5SD	5	60	80	12	25	25	152	25.5	27	FGC5
CFGSR/L2525-5SE	5	80	120	12	25	25	152	25.5	27	FGC5
CFGSR/L2525-5DA	5	30	40	22	25	25	162	26	27	FGC5
CFGSR/L2525-5DB	5	40	50	22	25	25	162	26	27	FGC5
CFGSR/L2525-5DC	5	50	60	22	25	25	162	26	27	FGC5
CFGSR/L2525-5DD	5	60	80	22	25	25	162	25.5	27	FGC5
CFGSR/L2525-5DE	5	80	120	22	25	25	162	25.5	27	FGC5
CFGSR/L2525-6SB	6	40	50	14	25	25	154	26	26	FGC6
CFGSR/L2525-6SC	6	50	60	14	25	25	154	26	26	FGC6
CFGSR/L2525-6SD	6	60	80	14	25	25	154	25.5	26	FGC6
CFGSR/L2525-6SE	6	80	120	14	25	25	154	25.5	26	FGC6
CFGSR/L3232-8SD	8	60	80	16	32	32	170	32.5	24.5	FGC8
CFGSR/L3232-8SE	8	80	120	16	32	32	170	32.5	24.5	FGC8

- ・ 右勝手ホルダは正回転で、左勝手のホルダは逆回転で使用します。
- ・ 各部品についてはセット形番に準じて在庫しており、部品のみの手配も可能です。
- ・ 右勝手のホルダ(CFGSR)には右勝手のブレード(FBR)、押え金(CFG-R)を、左勝手のホルダ(CFGSL)には左勝手のインサート(FBL)、押え金(CFG-L)をご使用ください。

参照ページ

インサート → C136, 標準切削条件 → C137