


TPS17

ねじ止め式直角肩加工用正面フライスカッタ、ASMT / ASGT17形インサート使用

A.R. = +9°, R.R. = -20°~ -7°

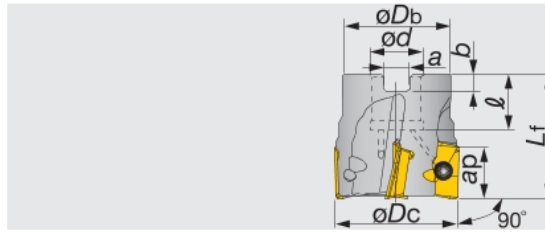

本図は右勝手(R)を示す。

形番	Max. ap	ϕD_c	z	Lf	ϕd	ℓ	a	b	Kg	エア穴	インサート
TPS17040RB	16.2	40	4	40	16	18	8.2	5.6	0.2	あり	AS*T1705...
TPS17040RB-E	16.2	40	4	40	16	19	8.4	5.6	0.2	なし	AS*T1705...
TPS17050RB	16.1	50	5	40	22	20	10	6	0.3	あり	AS*T1705...
TPS17050RB-E	16.1	50	5	40	22	20	10.4	6.3	0.3	なし	AS*T1705...
TPS17063RB	16	63	6	45	22	20	10	6	0.6	あり	AS*T1705...
TPS17063RB-E	16	63	6	45	22	20	10.4	6.3	0.6	なし	AS*T1705...
TPS17080RB	16	80	8	50	25.4	26	9.5	6	1.1	あり	AS*T1705...
TPS17100RB	16	100	9	63	31.75	32	12.7	8	2.2	あり	AS*T1705...
TPS17125RB	16	125	11	63	38.1	47	15.9	10	3.3	あり	AS*T1705...
TPS17160RB	16	160	12	63	50.8	47	19	11	5.5	あり	AS*T1705...

部品



形番	締付けねじ	焼きつき防止剤	カッタ締付けボルト	カッタ締付けボルト 1	カッタ締付けボルト 2	スパナ
TPS17040RB	CSPB-4S	M-1000	-	FSHM8-30H	-	IP-15D
TPS17040RB-E	CSPB-4S	M-1000	-	-	FSHM8-30	IP-15D
TPS17050RB	CSPB-4S	M-1000	-	CM10X30H	-	IP-15D
TPS17050RB-E	CSPB-4S	M-1000	-	-	CAP-CM10X1.5X30	IP-15D
TPS17063RB	CSPB-4S	M-1000	-	CM10X30H	-	IP-15D
TPS17063RB-E	CSPB-4S	M-1000	-	-	CAP-CM10X1.5X30	IP-15D
TPS17080RB	CSPB-4S	M-1000	-	CM12X30H	-	IP-15D
TPS17100RB	CSPB-4S	M-1000	-	CM16X40H	-	IP-15D
TPS17125RB	CSPB-4S	M-1000	TMBA-M20H	-	-	IP-15D
TPS17160RB	CSPB-4S	M-1000	TMBA-M24H	-	-	IP-15D

肩削り用

参照ページ

インサート → D105, 標準切削条件 → D106