


TME4400R/LI

くさび止め式正面フライスカッタ、切込み角:45°、四角形ポジンサート使用

A.R. = +24°, R.R. = -8° ~ -6°

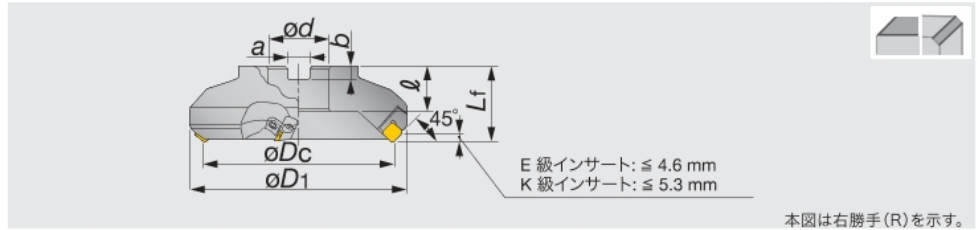


形番	Max. ap	øDc	z	øD1	Lf	od	ℓ	a	b	Kg	インサート
TME4403R/LI	4	80	4	101.5	50	25.4	26	9.5	6	1.43	SE*N1203...
TME4404R/LI	4	100	5	120.2	63	31.75	32	12.7	8	2.74	SE*N1203...
TME4405R/LI	4	125	6	145.2	63	38.1	38	15.9	10	4.04	SE*N1203...
TME4406R/LI	4	160	8	181.2	63	50.8	38	19	11	5.82	SE*N1203...
TME4408R/LI	4	200	10	220.5	63	47.625	38	25.4	14	9.18	SE*N1203...
TME4410R/LI	4	250	12	269.8	63	47.625	38	25.4	14	16.64	SE*N1203...
TME4412RI	4	315	14	334.4	63	47.625	38	25.4	14	25.72	SE*N1203...

※刃先高さLfはインサートSEEN12103AG*Nを使用した場合の値です。


平面加工用

アーバタイプ

TME4408/10R/LI

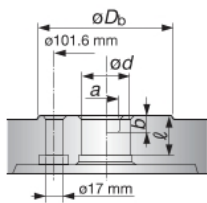


TME4412RI

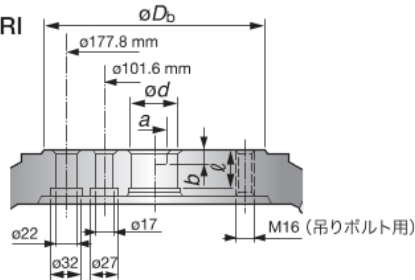

部品

形番	①ロケータ	④押え駒締付けねじ	②ロケータ締付けねじ	③インサート押え駒	スパナ
TME4403RI	LE444R	FDS-8S	CM4X0.7X14	WF444R	TP-4
TME4403LI	LE444L	FDS-8S	CM4X0.7X14	WF444L	TP-4
TME4404RI	LE444R	FDS-8S	CM4X0.7X14	WF444R	TP-4
TME4404LI	LE444L	FDS-8S	CM4X0.7X14	WF444L	TP-4
TME4405RI	LE444R	FDS-8S	CM4X0.7X14	WF444R	TP-4
TME4405LI	LE444L	FDS-8S	CM4X0.7X14	WF444L	TP-4
TME4406RI	LE446R	FDS-8S	CM4X0.7X14	WF444R	TP-4
TME4406LI	LE446L	FDS-8S	CM4X0.7X14	WF444L	TP-4
TME4408RI	LE446R	FDS-8S	CM4X0.7X14	WF444R	TP-4
TME4408LI	LE446L	FDS-8S	CM4X0.7X14	WF444L	TP-4
TME4410RI	LE446R	FDS-8S	CM4X0.7X14	WF444R	TP-4
TME4410LI	LE446L	FDS-8S	CM4X0.7X14	WF444L	TP-4
TME4412RI	LE446R	FDS-8S	CM4X0.7X14	WF444R	TP-4

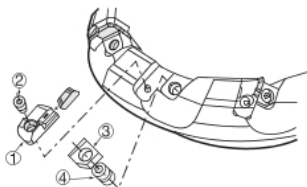

参照ページ

インサート → D163, 標準切削条件 → D164