




形番	AH725	D	d	ap	L	シャンク
TEC020A4-08C02-E32	●	2	2	8	32	円筒
TEC025A4-08C025-E32	●	2.5	2.5	8	32	円筒
TEC030A4-12C03-E38	●	3	3	12	38	円筒
TEC040A4-12C04-E50	●	4	4	12	50	円筒
TEC050A4-14C05-E50	●	5	5	14	50	円筒
TEC055A4-16C055-E50	●	5.5	5.5	16	50	円筒
TEC060A4-16C06-E50	●	6	6	16	50	円筒
TEC070A4-20C07-E60	●	7	7	20	60	円筒
TEC080A4-20C08-E60	●	8	8	20	60	円筒
TEC090A4-20C09-E60	●	9	9	20	60	円筒
TEC100A4-22C10-E72	●	10	10	22	72	円筒
TEC120A4-22C12-E73 (70)	●	12	12	22	73 (70)	円筒
TEC140A4-25C14-E75	●	14	14	25	75	円筒
TEC160A4-25C16-E82	●	16	16	25	82	円筒
TEC200A4-32C20-E100	●	20	20	32	100	円筒

TEC\*\*A4-\*\*C\*\*-E...

4枚刃、ねじれ角30°、エクストラロングタイプ

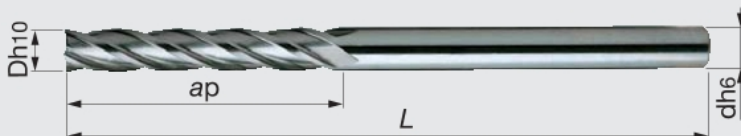

形番	AH725	D	d	ap	L	シャンク
TEC030A4-30C03-E75	●	3	3	30	75	円筒
TEC040A4-30C04-E75	●	4	4	30	75	円筒
TEC050A4-40C05-E100	●	5	5	40	100	円筒
TEC060A4-50C06-E150	●	6	6	50	150	円筒
TEC080A4-50C08-E150	●	8	8	50	150	円筒
TEC100A4-60C10-E150	●	10	10	60	150	円筒
TEC120A4-75C12-E150	●	12	12	75	150	円筒
TEC140A4-65C14-E150	●	14	14	65	150	円筒
TEC160A4-65C16-E150	●	16	16	65	150	円筒
TEC200A4-65C20-E150	●	20	20	65	150	円筒

●: 設定アイテム