


DMX L/D=2 (S type)

ソリッドドリル、先端角130°、油穴なし、シャンク径 = 工具径、L/D = 2、工具径 $\phi 3 - \phi 20$ mm

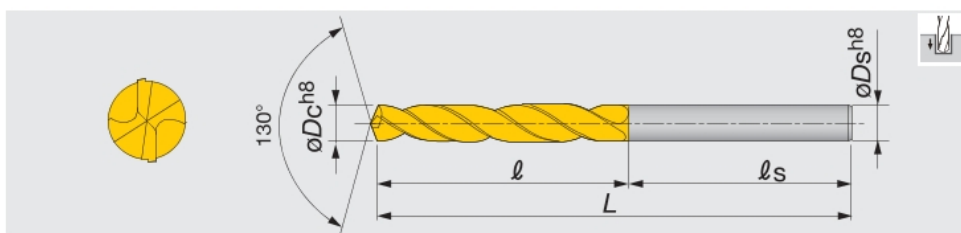

形番	ϕD_c	AH170	ϕD_s	ℓ	ℓ_s	L	形番	ϕD_c	AH170	ϕD_s	ℓ	ℓ_s	L
DMX030S	3	●	3	16	30	46	DMX093S	9.3	●	9.3	40	44	84
DMX031S	3.1	●	3.1	18	31	49	DMX094S	9.4	●	9.4	40	44	84
DMX032S	3.2	●	3.2	18	31	49	DMX095S	9.5	●	9.5	40	44	84
DMX033S	3.3	●	3.3	18	31	49	DMX096S	9.6	●	9.6	43	46	89
DMX034S	3.4	●	3.4	20	32	52	DMX097S	9.7	●	9.7	43	46	89
DMX035S	3.5	●	3.5	20	32	52	DMX098S	9.8	●	9.8	43	46	89
DMX036S	3.6	●	3.6	20	32	52	DMX099S	9.9	●	9.9	43	46	89
DMX037S	3.7	●	3.7	20	32	52	DMX100S	10	●	10	43	46	89
DMX038S	3.8	●	3.8	22	33	55	DMX101S	10.1	●	10.1	43	46	89
DMX039S	3.9	●	3.9	22	33	55	DMX102S	10.2	●	10.2	43	46	89
DMX040S	4	●	4	22	33	55	DMX103S	10.3	●	10.3	43	46	89
DMX041S	4.1	●	4.1	22	33	55	DMX104S	10.4	●	10.4	43	46	89
DMX042S	4.2	●	4.2	22	33	55	DMX105S	10.5	●	10.5	43	46	89
DMX043S	4.3	●	4.3	24	34	58	DMX106S	10.6	●	10.6	43	46	89
DMX044S	4.4	●	4.4	24	34	58	DMX107S	10.7	●	10.7	47	48	95
DMX045S	4.5	●	4.5	24	34	58	DMX108S	10.8	●	10.8	47	48	95
DMX046S	4.6	●	4.6	24	34	58	DMX109S	10.9	●	10.9	47	48	95
DMX047S	4.7	●	4.7	24	34	58	DMX110S	11	●	11	47	48	95
DMX048S	4.8	●	4.8	26	36	62	DMX111S	11.1	●	11.1	47	48	95
DMX049S	4.9	●	4.9	26	36	62	DMX112S	11.2	●	11.2	47	48	95
DMX050S	5	●	5	26	36	62	DMX113S	11.3	●	11.3	47	48	95
DMX051S	5.1	●	5.1	26	36	62	DMX114S	11.4	●	11.4	47	48	95
DMX052S	5.2	●	5.2	26	36	62	DMX115S	11.5	●	11.5	47	48	95
DMX053S	5.3	●	5.3	26	36	62	DMX116S	11.6	●	11.6	47	48	95
DMX054S	5.4	●	5.4	28	38	66	DMX117S	11.7	●	11.7	47	48	95
DMX055S	5.5	●	5.5	28	38	66	DMX118S	11.8	●	11.8	47	48	95
DMX056S	5.6	●	5.6	28	38	66	DMX119S	11.9	●	11.9	51	51	102
DMX057S	5.7	●	5.7	28	38	66	DMX120S	12	●	12	51	51	102
DMX058S	5.8	●	5.8	28	38	66	DMX121S	12.1	●	12.1	51	51	102
DMX059S	5.9	●	5.9	28	38	66	DMX122S	12.2	●	12.2	51	51	102
DMX060S	6	●	6	28	38	66	DMX123S	12.3	●	12.3	51	51	102
DMX061S	6.1	●	6.1	31	39	70	DMX124S	12.4	●	12.4	51	51	102
DMX062S	6.2	●	6.2	31	39	70	DMX125S	12.5	●	12.5	51	51	102
DMX063S	6.3	●	6.3	31	39	70	DMX126S	12.6	●	12.6	51	51	102
DMX064S	6.4	●	6.4	31	39	70	DMX127S	12.7	●	12.7	51	51	102
DMX065S	6.5	●	6.5	31	39	70	DMX128S	12.8	●	12.8	51	51	102
DMX066S	6.6	●	6.6	31	39	70	DMX129S	12.9	●	12.9	51	51	102
DMX067S	6.7	●	6.7	31	39	70	DMX130S	13	●	13	51	51	102
DMX068S	6.8	●	6.8	34	40	74	DMX131S	13.1	●	13.1	51	51	102
DMX069S	6.9	●	6.9	34	40	74	DMX132S	13.2	●	13.2	51	51	102
DMX070S	7	●	7	34	40	74	DMX133S	13.3	●	13.3	54	53	107
DMX071S	7.1	●	7.1	34	40	74	DMX134S	13.4	●	13.4	54	53	107
DMX072S	7.2	●	7.2	34	40	74	DMX135S	13.5	●	13.5	54	53	107
DMX073S	7.3	●	7.3	34	40	74	DMX136S	13.6	●	13.6	54	53	107
DMX074S	7.4	●	7.4	34	40	74	DMX137S	13.7	●	13.7	54	53	107
DMX075S	7.5	●	7.5	34	40	74	DMX138S	13.8	●	13.8	54	53	107
DMX076S	7.6	●	7.6	37	42	79	DMX139S	13.9	●	13.9	54	53	107
DMX077S	7.7	●	7.7	37	42	79	DMX140S	14	●	14	54	53	107
DMX078S	7.8	●	7.8	37	42	79	DMX141S	14.1	●	14.1	56	55	111
DMX079S	7.9	●	7.9	37	42	79	DMX142S	14.2	●	14.2	56	55	111
DMX080S	8	●	8	37	42	79	DMX143S	14.3	●	14.3	56	55	111
DMX081S	8.1	●	8.1	37	42	79	DMX144S	14.4	●	14.4	56	55	111
DMX082S	8.2	●	8.2	37	42	79	DMX145S	14.5	●	14.5	56	55	111
DMX083S	8.3	●	8.3	37	42	79	DMX146S	14.6	●	14.6	56	55	111
DMX084S	8.4	●	8.4	37	42	79	DMX147S	14.7	●	14.7	56	55	111
DMX085S	8.5	●	8.5	37	42	79	DMX148S	14.8	●	14.8	56	55	111
DMX086S	8.6	●	8.6	40	44	84	DMX149S	14.9	●	14.9	56	55	111
DMX087S	8.7	●	8.7	40	44	84	DMX150S	15	●	15	56	55	111
DMX088S	8.8	●	8.8	40	44	84	DMX151S	15.1	●	15.1	58	57	115
DMX089S	8.9	●	8.9	40	44	84	DMX152S	15.2	●	15.2	58	57	115
DMX090S	9	●	9	40	44	84	DMX153S	15.3	●	15.3	58	57	115
DMX091S	9.1	●	9.1	40	44	84	DMX154S	15.4	●	15.4	58	57	115
DMX092S	9.2	●	9.2	40	44	84	DMX155S	15.5	●	15.5	58	57	115

● : 設定アイテム