
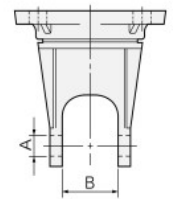
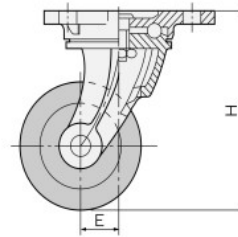


BR

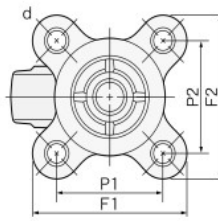

単位：mm

車輪径 D	型 式	車 輪 W	許容荷重	取付高 H	取付ピッチ P1×P2	プレート寸法 F1×F2	金具幅 B	偏心 E	取付穴径 d	軸径 A
75	75BR A	ゴム	70kg	112.5	65×65	91×91	40	25	11	10
	75BR B	ゴム (B入)								
	75BR FA	鉄	140kg							
	75BR FB	鉄 (B入)								
	75BR ULB	ウレタン (B入)								
	75BR MCB	MCナイロン (B入)								
100	100BR A	ゴム	100kg	140	85×85	113×113	47	30	11	12
	100BR B	ゴム (B入)								
	100BR FA	鉄	190kg							
	100BR FB	鉄 (B入)								
	100BR ULB	ウレタン (B入)	210kg							
	100BR MCB	MCナイロン (B入)								
125	125BR A	ゴム	150kg	168.5	100×100	128×128	52	40	11	17
	125BR B	ゴム (B入)								
	125BR FA	鉄	280kg							
	125BR FB	鉄 (B入)								
	125BR ULB	ウレタン (B入)								
	125BR MCB	MCナイロン (B入)								
150	150BR A	ゴム	180kg	195	100×100	128×128	56	40	11	20
	150BR B	ゴム (B入)								
	150BR FA	鉄	350kg							
	150BR FB	鉄 (B入)								
	150BR ULB	ウレタン (B入)								
	150BR MCB	MCナイロン (B入)								
180	180BR A	ゴム	200kg	225	110×110	144×144	57	45	11	20
	180BR B	ゴム (B入)								
	180BR FA	鉄	430kg							
	180BR FB	鉄 (B入)								
	180BR ULB	ウレタン (B入)								
	180BR MCB	MCナイロン (B入)								
200	200BR A	ゴム	220kg	250	120×120	156×156	60	50	14	20
	200BR B	ゴム (B入)								
	200BR FA	鉄	490kg							
	200BR FB	鉄 (B入)								
	200BR ULB	ウレタン (B入)								
	200BR MCB	MCナイロン (B入)								
230	230BR A	ゴム	270kg	290	140×140	180×180	66	60	14	25
	230BR B	ゴム (B入)								
250	250BR A	ゴム	300kg	300	140×140	180×180	66	60	14	25
	250BR B	ゴム (B入)								
	250BR FA	鉄	650kg							
	250BR FB	鉄 (B入)								
	250BR ULB	ウレタン (B入)								
	250BR MCB	MCナイロン (B入)								
300	300BR A	ゴム	350kg	350	160×160	204×204	70	65	14	25
	300BR B	ゴム (B入)								
	300BR FB	鉄 (B入)	830kg							
	300BR ULB	ウレタン (B入)								
	300BR MCB	MCナイロン (B入)								