

# カプラ




Order  
注文例

型式 (Type・No.)

SPU6


## ■メス継手

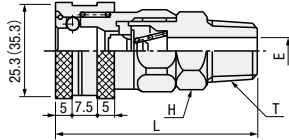

( )内の寸法はSM6の数値です。M 材質 SUS304

型式		T	L	E	H対辺
Type	No.	Rc (PT)			
SM	2	1/4	53.4	7	19
	3	3/8	55.7	8.9	
	4	1/2	59.6	10	
	6	3/4	67.1	16	


## ■おねじプラグ

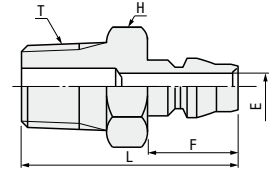

M 材質 SUS304

型式		T	L	E	F	H対辺
Type	No.	R (PT)				
PM	2	1/4	40.5	7.5	20.5	14
	3	3/8	41.5			
	4	1/2	46.5			
	6	3/4	52			


## ■メスユニオン

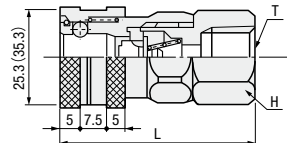

( )内の寸法はSF6の数値です。M 材質 SUS304

型式		T	L	H対辺
Type	No.	Rc (PT)		
SF	2	1/4	52.6	19
	3	3/8	52.7	21
	4	1/2	56.7	27
	6	3/4	63	32


## ■メスプラグ

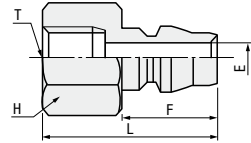

M 材質 SUS304

型式		T	L	E	F	H対辺
Type	No.	Rc (PT)				
PF	2	1/4	37.5	7.5	20.5	17
	4	1/2	42			
	6	3/4	47			


## ■油圧用継手

 

( )内の寸法はSH6の数値です。M 材質 SUS304

型式		適用管内径 (inch)	L	F	E	H
Type	No.					
SH	3	φ3/8	71.5	30.5	10.5	19
	4	φ1/2	76.6	35	13.7	
	6	φ3/4	87	40	20	
	25	φ5/16	66.6	25	9	

## ■油圧管プラグ

 

M 材質 SUS304

型式		適用管内径 (inch)	L	S	T	E	F	H
Type	No.							
PH	2	φ1/4	51.5	25	7	7.5	20.5	15
	3	φ3/8	56.5	30	10.5			
	4	φ1/2	61.5	35	13.7			
	6	φ3/4	73	40	20			
	25	φ5/16	51.5	25	9			