

サニタリー管用継手



Order
注文例


Type - No.
L31A - 1510

■溶接タイプ同芯異径



CAD 2D

Type	材質
L31A	SUS304
L31AS	SUS316L

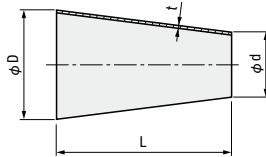


型式		適用管呼び径 (インチ)	D	φd	L	t
Type	No.					
L31A L31AS	1510	1 1/2×1	38.1	25.4	50.8	1.65
	2010	2×1				
	2015	2×1 1/2	50.8	38.1	50.8	
	2510	2 1/2×1		25.4	152.4	
	2515	2 1/2×1 1/2	63.5	38.1	101.6	
	2520	2 1/2×2		50.8	50.8	
	3010	3×1	76.2	25.4	203.2	
	3015	3×1 1/2		38.1	152.4	
	3020	3×2	50.8	101.6		
	3025	3×2 1/2	63.2	50.8		

■ショート偏芯異径



Type	材質
L32A	SUS304
L32AS	SUS316L

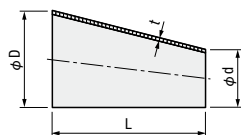

型式		適用管呼び径 (インチ)	D	d	L	t
Type	No.					
L32A L32AS	1005	1×1/2	25.4	12.7	50.8	1.65
	1008	1×3/4				
	1505*	1 1/2×1/2	38.1	12.7	101.6	
	1508	1 1/2×3/4				
	1510	1 1/2×1	50.8	25.4	50.8	
	2010	2×1				
	2015	2×1 1/2	50.8	38.1	50.8	
	2510	2 1/2×1				
	2515	2 1/2×1 1/2	63.5	38.1	101.6	
	2520	2 1/2×2				
	3010	3×1	76.2	25.4	203.2	
	3015	3×1 1/2				
	3020	3×2	101.6	50.8	101.6	
	3025	3×2 1/2				
	4020	4×2	101.6	50.8	203.2	
	4025	4×2 1/2				
	4030	4×3	76.2	101.6		


*: No.1505はL32ASに適用しません。

■フェールタイプ90° ショートエルボ



CAD 2D

Type	材質
2CMPA	SUS304
2CMPAS	SUS316L

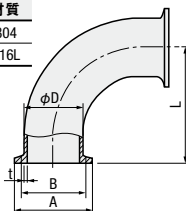


型式		適用管呼び径 (インチ)	A	B	D	L	t
Type	No.						
2CMPA 2CMPAS	10	1	50.5	43.5	25.4	50.8	1.65
	15	1 1/2					
	20	2	64	56.5	50.8	88.9	
	25	2 1/2	77.5	70.5	63.5	108.0	
	30	3	91	83.5	76.2	127.0	
	40	4	119	110	101.6	168.2	

■フェールタイプ ロングチーズ



CAD 2D

Type	材質
7MPA	SUS304
7MPAS	SUS316L

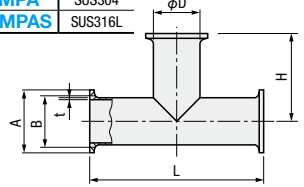


型式		適用管呼び径 (インチ)	A	B	D	L	H	t
Type	No.							
7MPA 7MPAS	10	1	50.5	43.5	25.4	120.6	60.3	1.65
	15	1 1/2						
	20	2	64	56.5	50.8	177.8	88.9	
	25	2 1/2	77.5	70.5	63.5	190.6	95.3	
	30	3	91	83.5	76.2	228.4	114.2	
	40	4	119	110	101.6	228.4	114.2	

■溶接フェール



CAD 2D

Type	材質
PA	SUS304
PAS	SUS316L

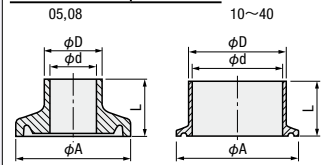

型式		適用管呼び径 (インチ)	d	D	A	L		
Type	No.					14AMPA□	14MMPA□	14WMPA□
14AMPA 14AMPAS 14MMPA 14MMPAS 14WMPA 14WMPAS	05	1/2	9.45	12.75	25.2	28.6	21.5	12.7
	08	3/4	15.75	19.05				
	10	1	22.2	25.4				
	15	1 1/2	34.9	38.1				
	20	2	47.6	50.8	64			
	25	2 1/2	60.3	63.5	77.5			
	30	3	73	76.2	91			
	40	4	97.6	101.6	119			