

# サニタリー管用継手

—キャップ / ガasket / クランプ 3A規格—



Order  
注文例


Type — No.  
16AMPA — 10

## ■キャップ



CAD 2D

 Type	材質
16AMPA	SUS304
16AMPAS	SUS316L




型式		適用管呼び径 (インチ)	A	t
Type	No.			
16AMPA 16AMPAS	05	1/2~3/4	25.2	6.3
	10	1~1 1/2	50.5	
	20	2	64	
	25	2 1/2	77.5	7.9
	30	3	91	
	40	4	119	

## ■重量型シングルリベットクランプ



CAD 2D

Type	材質
13MHHD	SUS304

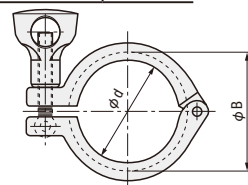


型式		適用管呼び径 (インチ)	d	B
Type	No.			
13MHHD	10	1~1 1/2	44.4	53.6
	20	2	57.8	67
	25	2 1/2	71.4	80.6
	30	3	84	94.2
	35	3 1/2	99	109.2
	40	4	110	122.2
	60	6	155.4	170.4

## ■フラットガスケット



CAD 2D

Type	材質	Type	材質
13PGAE	EPDM	13PGAP	PTFE
13PGAS	SILICON	13PGAPE	PTFE+EPDM
13PGAV	VITON		

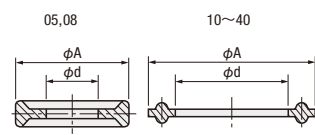


型式		適用管呼び径 (インチ)	d	A
Type	No.			
13PGAE 13PGAS 13PGAV 13PGAP 13PGAPE	05	1/2	9.9	21.8
	08	3/4	16.3	
	10	1	22.7	
	15	1 1/2	35.9	50
	20	2	48.6	
	25	2 1/2	61.3	
	30	3	74	
	40	4	98.6	

## ■高圧クランプ



CAD 2D

Type	材質
13MHPD	SUS304

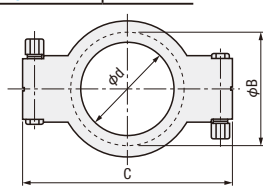

型式		適用管呼び径 (インチ)	d	B	C
Type	No.				
13MHPD	05	1/2~3/4	20	28	55
	10	1~1 1/2	43.3	52	103
	20	2	56.4	65.5	114.5
	25	2 1/2	69.5	79	127
	30	3	77.5	92.5	140.6
	40	4	108.8	120.5	165