

サニタリー管用継手

—BPE規格—




Order
注文例

Type — No.
DT7BS — 10

■90°ショートエルボ BPE規格



| Type | 材質 | 表面粗さ |
|-------|---------|------|
| DT7BS | SUS316L | SF1 |
| DT7ES | | SF4 |

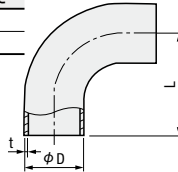


| 型式 | | 適用管呼び径 (インチ) | D | L | t | |
|----------------|-----|-----------------|-------|-------|------|------|
| Type | No. | | | | | |
| DT7BS DT7ES | 05 | 1/2 | 12.7 | 76.2 | 1.65 | |
| | 08 | 3/4 | 19.05 | | | |
| | 10 | 1 | 25.4 | | | |
| | 15 | 1 1/2 | 38.1 | | | |
| | 20 | 2 | 50.8 | 95.3 | | |
| | 25 | 2 1/2 | 63.5 | 120.7 | | |
| | 30 | 3 | 76.2 | 158.8 | | |
| | 40 | 4 | 101.6 | 203.2 | | 2.10 |

■45°ショートエルボ BPE規格



| Type | 材質 | 表面粗さ |
|-------|---------|------|
| DT8BS | SUS316L | SF1 |
| DT8ES | | SF4 |

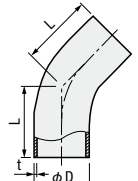


| 型式 | | 適用管呼び径 (インチ) | D | L | t | |
|----------------|-----|-----------------|-------|-------|------|------|
| Type | No. | | | | | |
| DT8BS DT8ES | 05 | 1/2 | 12.7 | 57.2 | 1.65 | |
| | 08 | 3/4 | 19.05 | | | |
| | 10 | 1 | 25.4 | | | |
| | 15 | 1 1/2 | 38.1 | | | |
| | 20 | 2 | 50.8 | 63.5 | | |
| | 25 | 2 1/2 | 63.5 | 85.7 | | |
| | 30 | 3 | 76.2 | 92.1 | | |
| | 40 | 4 | 101.6 | 114.3 | | 2.10 |

■溶接U形ロングエルボ



| Type | 材質 | 表面粗さ |
|------|---------|------|
| UBS | SUS316L | SF1 |
| UES | | SF4 |

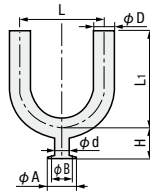


| 型式 | | 適用管呼び径 (インチ) | A | B | D | d | L | L ₁ | H |
|------------|------|-----------------|------|------|------|-------|--------|----------------|-------|
| Type | No. | | | | | | | | |
| UBS UES | 1008 | 1 × 3/4 | 25 | 20 | 25.4 | 19.05 | 114.30 | 95.25 | 25.58 |
| | 1510 | 1 1/2 × 1 | 50.5 | 43.5 | 38.1 | 25.4 | | 114.30 | 34.93 |
| | 1508 | 1 1/2 × 3/4 | 25 | 20 | 38.1 | 19.05 | | | |
| | 2015 | 2 × 1 1/2 | 50.5 | 43.5 | 50.8 | 38.1 | 152.40 | | |
| | 2010 | 2 × 1 | | | | 25.4 | | 127.00 | 41.28 |
| | 2008 | 2 × 3/4 | 25 | 20 | 25.4 | 19.05 | | | |

■同芯異径



| Type | 材質 | 表面粗さ |
|--------|---------|------|
| DT11BS | SUS316L | SF1 |
| DT11ES | | SF4 |

 


| 型式 | | 適用管呼び径 (インチ) | D | d | L | t |
|------------------|------|-----------------|-------|-------|-------|------|
| Type | No. | | | | | |
| DT11BS DT11ES | 0805 | 3/4 × 1/2 | 19.05 | 12.7 | 101.6 | 1.65 |
| | 1005 | 1 × 1/2 | | | 114.3 | |
| | 1008 | 1 × 3/4 | | | 101.6 | |
| | 1505 | 1 1/2 × 1/2 | 25.4 | 12.7 | 139.7 | |
| | 1508 | 1 1/2 × 3/4 | | | 127 | |
| | 1510 | 1 1/2 × 1 | | | 127 | |
| | 2005 | 2 × 1/2 | 38.1 | 19.05 | 196.9 | |
| | 2008 | 2 × 3/4 | | | 184.2 | |
| | 2010 | 2 × 1 | | | 184.2 | |
| | 2015 | 2 × 1 1/2 | 50.8 | 25.4 | 133.4 | |
| | 2505 | 2 1/2 × 1/2 | | | 247.7 | |
| | 2508 | 2 1/2 × 3/4 | | | 235.0 | |
| | 2510 | 2 1/2 × 1 | 63.5 | 38.1 | 184.2 | |
| | 2515 | 2 1/2 × 1 1/2 | | | 139.7 | |
| | 2520 | 2 1/2 × 2 | | | 139.7 | |
| | 3010 | 3 × 1 | 76.2 | 25.4 | 285.8 | |
| | 3015 | 3 × 1 1/2 | | | 235 | |
| | 3020 | 3 × 2 | | | 190.5 | |
| | 3025 | 3 × 2 1/2 | 101.6 | 38.1 | 139.7 | |
| | 4015 | 4 × 1 1/2 | | | 342.9 | |
| | 4020 | 4 × 2 | | | 298.5 | |
| | 4025 | 4 × 2 1/2 | 101.6 | 63.5 | 247.7 | |
| | 4030 | 4 × 3 | | | 196.9 | |

■異径チーズ



| Type | 材質 | 表面粗さ |
|--------|---------|------|
| DT10BS | SUS316L | SF1 |
| DT10ES | | SF4 |

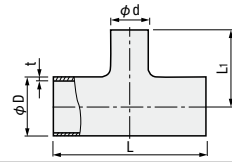


| 型式 | | 適用管呼び径 (インチ) | D | d | L | L ₁ | t | |
|------------------|------|-----------------|-------|-------|-------|----------------|------|-------|
| Type | No. | | | | | | | |
| DT10BS DT10ES | 1005 | 1 × 1/2 | 25.4 | 12.7 | 108.0 | 54.0 | 1.65 | |
| | 1008 | 1 × 3/4 | | | | | | 19.05 |
| | 1505 | 1 1/2 × 1/2 | | | | | | 12.7 |
| | 1508 | 1 1/2 × 3/4 | | | | | | 19.05 |
| | 1510 | 1 1/2 × 1 | 25.4 | 120.6 | 63.0 | | | |
| | 2005 | 2 × 1/2 | 12.7 | | | | | |
| | 2008 | 2 × 3/4 | 19.05 | | | | | |
| | 2010 | 2 × 1 | 25.4 | | | | | |
| | 2015 | 2 × 1 1/2 | 38.1 | 146.0 | 66.7 | | | |
| | 2510 | 2 1/2 × 1 | 25.4 | | | | | |
| | 2515 | 2 1/2 × 1 1/2 | 38.1 | | | | | |
| | 2520 | 2 1/2 × 2 | 50.8 | | | | | |
| | 3015 | 3 × 1 1/2 | 38.1 | 171.4 | 79.4 | | | |
| | 3020 | 3 × 2 | 50.8 | | | | | |
| | 3025 | 3 × 2 1/2 | 63.5 | | | | | |
| | 4020 | 4 × 2 | 50.8 | | | | | |
| | 4025 | 4 × 2 1/2 | 101.6 | 63.5 | 209.6 | 98.4 | | |
| | 4030 | 4 × 3 | 76.2 | | | | | |

■同径ロングチーズ



| Type | 材質 | 表面粗さ |
|-------|---------|------|
| DT9BS | SUS316L | SF1 |
| DT9ES | | SF4 |

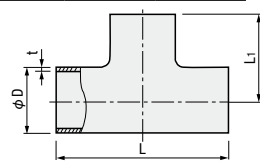

| 型式 | | 適用管呼び径 (インチ) | D | L | L ₁ | t | |
|----------------|-----|-----------------|-------|-------|----------------|------|------|
| Type | No. | | | | | | |
| DT9BS DT9ES | 05 | 1/2 | 12.7 | 95.2 | 47.6 | 1.65 | |
| | 08 | 3/4 | 19.05 | 101.6 | 50.8 | | |
| | 10 | 1 | 25.4 | 108.0 | 54 | | |
| | 15 | 1 1/2 | 38.1 | 120.6 | 60.3 | | |
| | 20 | 2 | 50.8 | 146.0 | 73 | | |
| | 25 | 2 1/2 | 63.5 | 158.8 | 79.4 | | |
| | 30 | 3 | 76.2 | 171.4 | 85.7 | | |
| | 40 | 4 | 101.6 | 209.6 | 104.8 | | 2.10 |