

サニタリー管用継手

—BPE規格—



 
Order
注文例

Type — No.
DT1EBS — 1005

■偏心異径




Type	材質	表面粗さ
DT1EBS	SUS316L	SF1
DT1EES		SF4



■90°フェールタイプエルボ



Type	材質	表面粗さ
DT16BS	SUS316L	SF1
DT16ES		SF4

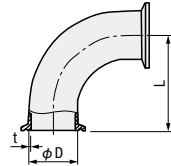


型式		適用管呼び径 (インチ)	D	d	L	t
Type	No.					
DT1EBS DT1EES	0805	3/4×1/2	19.05	12.7	101.6	1.65
	1005	1×1/2	25.4	17.8	114.3	
	1008	1×3/4	25.4	19.05	101.6	
	1505	1 1/2×1/2	38.1	12.7	139.7	
	1508	1 1/2×3/4	38.1	19.05	127	
	1510	1 1/2×1	38.1	25.4	127	
	2005	2×1/2	50.8	12.7	196.9	
	2008	2×3/4	50.8	19.05	184.2	
	2010	2×1	50.8	25.4	184.2	
	2015	2×1 1/2	50.8	38.1	133.4	
	2505	2 1/2×1/2	63.5	12.7	247.7	
	2508	2 1/2×3/4	63.5	19.05	235.0	
	2510	2 1/2×1	63.5	25.4	235.0	
	2515	2 1/2×1 1/2	63.5	38.1	184.2	
	2520	2 1/2×2	63.5	50.8	139.7	
	3010	3×1	76.2	25.4	285.8	
	3015	3×1 1/2	76.2	38.1	235	
	3020	3×2	76.2	50.8	190.5	
	3025	3×2 1/2	76.2	63.5	139.7	
	4015	4×1 1/2	101.6	38.1	342.9	
4020	4×2	101.6	50.8	298.5		
4025	4×2 1/2	101.6	63.5	247.7		
4030	4×3	101.6	76.2	196.9		

型式		適用管呼び径 (インチ)	D	L	t
Type	No.				
DT16BS DT16ES	05	1/2	12.7	41.3	1.65
	08	3/4	19.05	41.3	
	10	1	25.4	50.8	
	15	1 1/2	38.1	69.9	
	20	2	50.8	88.9	
	25	2 1/2	63.5	108	
	30	3	76.2	127	
	40	4	101.6	168.3	

■同径ショートチース



Type	材質	表面粗さ
DT15BS	SUS316L	SF1
DT15ES		SF4

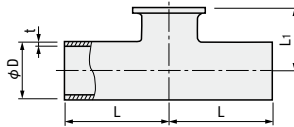


型式		適用管呼び径 (インチ)	D	L	L1	t
Type	No.					
DT15BS DT15ES	05	1/2	12.7	47.6	25.4	1.65
	08	3/4	19.05	50.8	28.6	
	10	1	25.4	54.0	28.6	
	15	1 1/2	38.1	60.3	34.9	
	20	2	50.8	73.0	41.3	
	25	2 1/2	63.5	79.4	47.6	
	30	3	76.2	85.7	54.0	
	40	4	101.6	104.8	69.9	

■フェールタイプ同長チース



Type	材質	表面粗さ
DT18BS	SUS316L	SF1
DT18ES		SF4

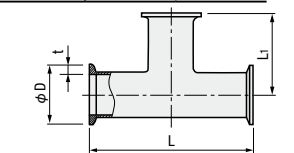


型式		適用管呼び径 (インチ)	D	L	L1	t
Type	No.					
DT18BS DT18ES	05	1/2	12.7	114.4	57.2	1.65
	08	3/4	19.05	120.6	60.3	
	10	1	25.4	133.4	66.7	
	15	1 1/2	38.1	146.0	73.0	
	20	2	50.8	171.4	85.7	
	25	2 1/2	63.5	184.2	92.1	
	30	3	76.2	196.8	98.4	
	40	4	101.6	241.4	120.7	

■溶接フェール



Type	材質	表面粗さ
BS	SUS316L	SF1
ES		SF4

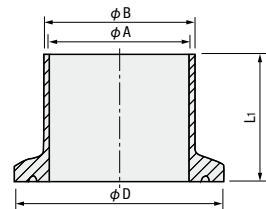


型式		適用管呼び径 (インチ)	A	B	D	L1	
Type	No.					14AMP	14AWFES
14AMPBS 14AMPES 14AWFES 14AWFBS	05	1/2	9.4	12.7	25	28.6	44.5
	08	3/4	15.7	19.1	25		
	10	1	22.1	25.4	50.5		
	15	1 1/2	34.8	38.1	50.5		
	20	2	47.5	50.8	64.0	57.2	
	25	2 1/2	60.2	63.5	77.5		
	30	3	72.9	76.2	91.0		
	40	4	97.4	101.6	119		

■キャップ



Type	材質	表面粗さ
16AMPBS	SUS316L	SF1
16AMPES		SF4

 

型式		適用管呼び径 (インチ)	A	L
Type	No.			
16AMPBS 16AMPES	05	1/2	25.4	6
	10	1	50.5	6
	20	2	64.0	6.3
	25	2 1/2	77.5	6.3
	30	3	91.0	6.3
40	4	119.0	7.9	