



ミスミ

APMシリーズ 外形図 詳細図 穴加工有効寸法


APMシリーズ ⑨79ページ

外形図・詳細図


(単位: mm)

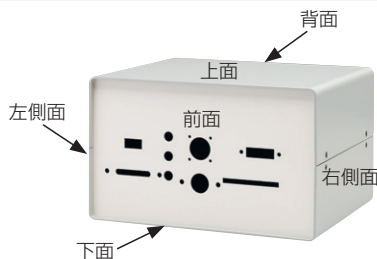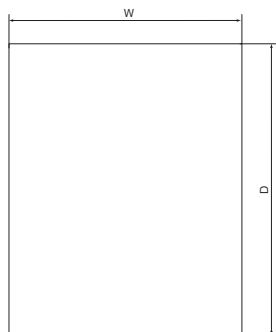


取付金具

 

D寸法	A	B
100~130	20	60
140~190	20	100
200~250	20	160

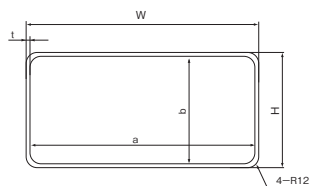


D寸法	a	b	t
100~200	外形-6	外形-6	3.0
210~250	外形-7	外形-7	3.5

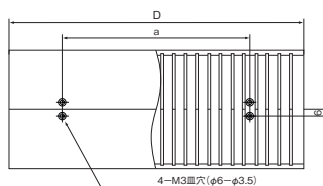


D寸法(奥行き)	100~130	140~190	200~250
a	50	90	150

上下カバー断面図

t=3

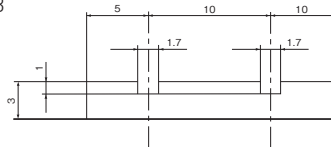

t=3.5

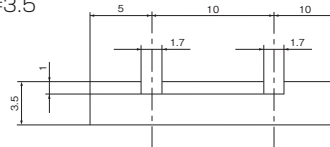

穴加工有効寸法

(単位: mm)

