


SSTD ショート 外部給油タイプ

● No.SSDのTiNコーティングタイプです。

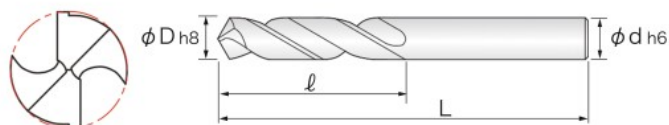

直径許容差
 $1 \leq D \leq 3$ 0~-0.014
 $3 < D \leq 6$ 0~-0.018
 $6 < D \leq 10$ 0~-0.022
 $10 < D \leq 18$ 0~-0.027
 $18 < D \leq 30$ 0~-0.033

超微粒子 TiNコート 右ねじれ 30° 刃数2 先端角 118°

切削条件表P124

超微粒子 TiNコート 右ねじれ 30° 刃数2 先端角 118°

在庫	型番	直径 ϕD	溝長 ℓ	全長 L
◎	SSTD111	11.1	65	120
◎	SSTD112	11.2	65	120
◎	SSTD113	11.3	65	120
◎	SSTD115	11.5	65	120
◎	SSTD118	11.8	65	120
◎	SSTD119	11.9	65	120
◎	SSTD120	12.0	65	120
◎	SSTD124	12.4	70	125
◎	SSTD125	12.5	70	125
◎	SSTD130	13.0	75	130

在庫	型番	直径 ϕD	溝長 ℓ	全長 L
◎	SSTD080	8.0	50	85
◎	SSTD081	8.1	50	85
◎	SSTD082	8.2	50	85
◎	SSTD083	8.3	50	85
◎	SSTD084	8.4	50	85
◎	SSTD085	8.5	50	85
◎	SSTD086	8.6	50	95
◎	SSTD087	8.7	50	95
◎	SSTD088	8.8	50	95
◎	SSTD089	8.9	50	95
◎	SSTD090	9.0	50	95
◎	SSTD091	9.1	50	95
◎	SSTD092	9.2	50	95
◎	SSTD093	9.3	50	95
◎	SSTD094	9.4	50	95
◎	SSTD095	9.5	50	95
◎	SSTD096	9.6	50	95
◎	SSTD097	9.7	50	95
◎	SSTD098	9.8	50	95
◎	SSTD099	9.9	55	100
◎	SSTD100	10.0	55	100
◎	SSTD101	10.1	55	115
◎	SSTD102	10.2	55	115
◎	SSTD103	10.3	55	115
◎	SSTD104	10.4	55	115
◎	SSTD105	10.5	55	115
◎	SSTD106	10.6	60	115
◎	SSTD107	10.7	60	115
◎	SSTD108	10.8	60	115
◎	SSTD109	10.9	60	115
◎	SSTD110	11.0	60	115

◎国内在庫品

被削材種	鋳鉄	炭素鋼	合金鋼	工具鋼	調質鋼	ステンレス鋼	アルミ合金	銅合金	チタン合金	耐熱合金	樹脂
	FC、FCD	S50C	SCM	SKD	NAK	SUS304	AL	Cu	Ti6Al4V	インコネル	ガラス繊維 含まず
硬度	~350HB	~225HB	~325HB	~32HRC	~48HRC	~35HRC					
型番											
SSTD	○	○	○	○			◎	○			