






Turning Inserts - Positive TCMT (Triangle)

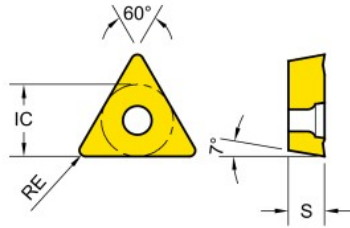

Series	IC	S
TC** 1102	6.350	2.38
TC** 16T3	9.525	3.97

EDP 2200..

● : Stock item ○ : Order made item

TCMT	Designation	RE	Fn (mm/rev.)	Ap (mm)	K10	P05	P10	P15	P10	P20	P30	P20	M25	M15	M30	M40	S10	P15	M15	N20	N20		
					K20	K30	K30	K30	K30	K30	K30	K30	K30	K30	K30	K30	K30	K30	K30	K30	K30	K30	K30
NEW -MF  Stainless steel Finishing	TCMT 110204 - MF	0.4	0.07 ~ 0.20	0.20 ~ 2.0																			
	TCMT 110208 - MF	0.8	0.07 ~ 0.20	0.30 ~ 2.0																			
	TCMT 16T304 - MF	0.4	0.06 ~ 0.25	0.10 ~ 2.0										●	●	●	●	●	●	●	●	●	●
	TCMT 16T308 - MF	0.8	0.08 ~ 0.30	0.15 ~ 2.0										●	●	●	●	●	●	●	●	●	●
NEW -MM  Stainless steel Medium	TCMT 16T304 - MM	0.4	0.08 ~ 0.25	0.25 ~ 3.0									●	●	●	●	●	●	●	●	●	●	
	TCMT 16T308 - MM	0.8	0.10 ~ 0.30	0.50 ~ 3.0									●	●	●	●	●	●	●	●	●	●	
NEW -PF  Cermet Medium	TCMT 16T304 - PF	0.4	0.06 ~ 0.25	0.10 ~ 2.0																		●	
	TCMT 16T308 - PF	0.8	0.08 ~ 0.30	0.15 ~ 2.0																			●
NEW -PM  Cermet Medium	TCMT 16T304 - PM	0.4	0.08 ~ 0.25	0.25 ~ 3.0																		●	
	TCMT 16T308 - PM	0.8	0.10 ~ 0.30	0.50 ~ 3.0																			●