


1008

メス スイベル コネクター Female swivel connector

Internal pipe/PF30° MIS swivel

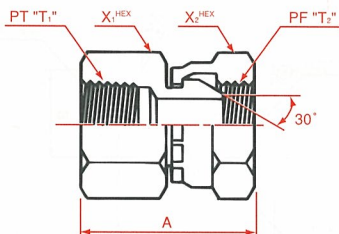


呼称サイズ	T ₁	T ₂	A	X ₁	X ₂
02-04	1/8	1/4	32	17	19
04	1/4	1/4	35	19	19
04-06	1/4	3/8	37	19	22
06	3/8	3/8	39	22	22
06-04	3/8	1/4	37	22	19
06-08	3/8	1/2	41	22	27
08	1/2	1/2	44.5	27	27
08-06	1/2	3/8	42	27	22
08-12	1/2	3/4	46.5	27	36
12	3/4	3/4	49.5	36	36
12-08	3/4	1/2	47	36	27
12-16	3/4	1	51.5	36	41
16	1	1	53.5	41	41
16-12	1	3/4	51.5	41	36

1061

オス スイベル45° エルボ Male 45° union elbow

External pipe/PF30° MIS swivel

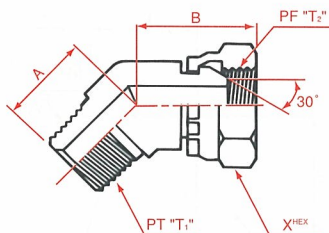

呼称サイズ	T ₁	T ₂	A	X ₁	X ₂
02-04	1/8	1/4	19	22	19
04	1/4	1/4	19	21	19
04-06	1/4	3/8	22	25	22
06	3/8	3/8	22	26	22
06-04	3/8	1/4	22	23	19
06-08	3/8	1/2	27	29	27
08	1/2	1/2	27	28	27
08-06	1/2	3/8	27	27	22
08-12	1/2	3/4	30	33	36
12	3/4	3/4	30	32	36
12-08	3/4	1/2	30	30	27
12-16	3/4	1	34	37	41
16	1	1	34	36	41
16-12	1	3/4	34	35	36