


ハイパーバニシングドリル AH10

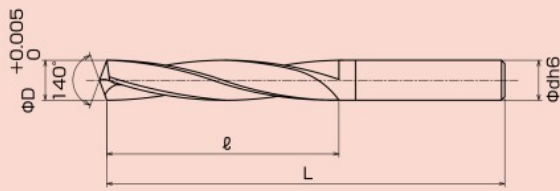

首形状詳細図(ストレートシャンク)



HPD○○○○K-○○ Φ2.75~4.7mm

商品コード	D 外径	ℓ 溝長	L 全長	d シャンク径	首形状	在庫	標準価格(円)
★HPD0275K	2.75	20	60	4	A	●	8,500
HPD0280K	2.8	20	60	4	A	●	11,200
HPD0290K	2.9	20	60	4	A	●	11,200
HPD0299K	2.99	25	70	4	A	●	10,600
HPD02995K	2.995	25	70	4	A	●	10,600
HPD0300K	3.0	25	70	4	A	●	8,500
HPD03005K	3.005	25	70	4	A	●	10,600
HPD0301K	3.01	25	70	4	A	●	10,600
HPD03015K	3.015	25	70	4	A	●	10,600
HPD0302K	3.02	25	70	4	A	●	10,600
HPD0310K	3.1	30	75	4	A	●	11,200
HPD0320K	3.2	30	75	4	A	●	11,200
◆HPD0330K	3.3	30	75	4	A	●	9,000
HPD0340K	3.4	30	75	4	A	●	11,800
HPD0350K	3.5	30	75	4	A	●	11,800
HPD0360K	3.6	30	75	4	A	●	11,800
★HPD0366K	3.66	30	75	4	A	●	9,000
HPD0370K	3.7	30	75	4	A	●	11,800
◆HPD0380K	3.8	30	75	4	A	●	11,800
HPD0390K	3.9	30	75	4	A	●	11,800
HPD0399K	3.99	30	75	4	A	●	11,800
HPD03995K	3.995	30	75	4	A	●	11,800
HPD0400K	4.0	30	75	4	B	●	9,000
HPD0400K-06	4.0	30	75	6	A	●	9,000
HPD04005K	4.005	35	80	6	A	●	11,800
HPD0401K	4.01	35	80	6	A	●	11,800
HPD04015K	4.015	35	80	6	A	●	11,800
HPD0402K	4.02	35	80	6	A	●	11,800
HPD0410K	4.1	35	80	6	A	●	12,300
◆HPD0420K	4.2	35	80	6	A	●	9,500
HPD0430K	4.3	35	80	6	A	●	12,300
HPD0440K	4.4	35	80	6	A	●	12,300
HPD0450K	4.5	35	80	6	A	●	12,300
★HPD0460K	4.6	35	80	6	A	●	9,700
HPD0470K	4.7	35	80	6	A	●	12,300

◆は、切削タップ並目2級下穴用です。

●特殊品、コーティング対応可能です。

HPD○○○○K-○○ Φ4.8~6.9mm

商品コード	D 外径	ℓ 溝長	L 全長	d シャンク径	首形状	在庫	標準価格(円)
HPD0480K	4.8	35	80	6	A	●	12,300
HPD0490K	4.9	35	80	6	A	●	12,300
HPD0499K	4.99	35	80	6	A	●	12,900
HPD04995K	4.995	35	80	6	A	●	12,900
◆HPD0500K	5.0	35	80	6	A	●	9,700
HPD05005K	5.005	35	80	6	A	●	12,900
HPD0501K	5.01	35	80	6	A	●	12,900
HPD05015K	5.015	35	80	6	A	●	12,900
HPD0502K	5.02	35	80	6	A	●	12,900
HPD0510K	5.1	42	90	6	A	●	13,400
HPD0520K	5.2	42	90	6	A	●	13,400
HPD0530K	5.3	42	90	6	A	●	13,400
HPD0540K	5.4	42	90	6	A	●	13,400
★HPD0550K	5.5	42	90	6	A	●	10,400
HPD0560K	5.6	42	90	6	A	●	13,400
HPD0570K	5.7	42	90	6	A	●	13,400
HPD0580K	5.8	42	90	6	A	●	13,400
HPD0590K	5.9	42	90	6	A	●	13,400
HPD0599K	5.99	42	90	6	A	●	14,000
HPD05995K	5.995	42	90	6	A	●	14,000
◆HPD0600K	6.0	42	90	6	B	●	10,900
HPD0600K-08	6.0	42	90	8	A	●	10,900
HPD06005K	6.005	45	95	8	A	●	14,000
HPD0601K	6.01	45	95	8	A	●	14,000
HPD06015K	6.015	45	95	8	A	●	14,000
HPD0602K	6.02	45	95	8	A	●	14,000
HPD0610K	6.1	45	95	8	A	●	14,600
HPD0620K	6.2	45	95	8	A	●	14,600
HPD0630K	6.3	45	95	8	A	●	14,600
HPD0640K	6.4	45	95	8	A	●	14,600
★HPD0650K	6.5	45	95	8	A	●	14,600
HPD0660K	6.6	45	95	8	A	●	14,600
HPD0670K	6.7	45	95	8	A	●	14,600
◆HPD0680K	6.8	45	95	8	A	●	11,900
HPD0690K	6.9	45	95	8	A	●	14,600

★は、転造タップ並目2級下穴用です。