



UHB型


重荷重用ウレタンゴム車輪

重荷重用ウレタンゴム車輪 (UHB型)

(単位: mm)



UHB200x90

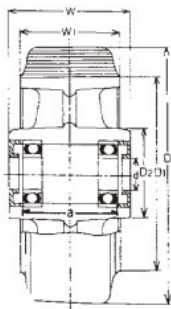

品名	車輪外径 D	許容荷重 (kg)	車輪巾 W ₁	ボス巾 W	軸径 d	ベアリング	リム径 D ₁	ボス径 D ₂	ベアリング当り a	アーム数	自重 (kg)
UHB100x50	100	330	51	54	17	6203	80	59	42	ベタ	1.7
UHB100x65	100	380	64	70	17	6203	80	59	54	ベタ	2.2
UHB130x50	130	380	51	54	20	6204	110	60	38	ベタ	2.3
UHB130x65	130	450	64	70	20	6204	110	60	54	ベタ	3.2
UHB150x50	150	430	51	57	25	6205	128	61	41	ベタ	2.5
UHB150x65	150	560	64	70	25	6205	128	65	54	ベタ	3.3
UHB150x75	150	670	76	82	25	6205	128	71	66	ベタ	3.9
UHB150x100	150	870	102	108	30	6206	128	75	90	ベタ	6.6
UHB180x50	180	480	51	57	25	6205	155	67	41	4	3.5
UHB180x65	180	620	64	70	25	6205	155	67	54	4	4.3
UHB180x75	180	750	76	82	25	6205	155	68	66	4	5.3
UHB200x50	200	530	51	57	25	6205	176	67	41	ベタ	3.8
UHB200x65	200	680	64	70	25	6205	176	69	54	4	5.0
UHB200x75	200	790	76	82	25	6205	176	68	66	4	5.6
UHB200x90	200	900	89	95	30	6206	176	81	77	4	7.9
UHB200x100	200	1200	102	114	40	6308	170	98	94	4	10.3
UHB250x65	250	830	64	70	25	6305	220	83	52	5	7.5
UHB250x75	250	1000	76	82	30	6206	220	84	64	5	8.7
UHB250x90	250	1250	89	102	30	6206	220	83	84	5	12.3
※ UHB250x100	250	1400	102	114	40	6208	220	96	94	5	15.4
UHB250x125	250	1600	125	133	50	6210	220	108	113	5	16.8
UHB300x65	300	980	64	82	30	6206	260	85	64	5	9.3
UHB300x75	300	1130	76	82	30	6206	260	85	64	5	10.9
UHB300x90	300	1350	89	99	30	6206	260	85	81	5	13.0
※ UHB300x100 ^{#6}	300	1500	102	114	30	6306	260	96	94	5	14.6
※ UHB300x100 ^{#8}	300	1500	102	114	40	6208	260	96	94	5	13.6
UHB300x130	300	2000	125	133	50	6210	260	108	113	5	18.5
UHB300x150	300	2500	150	160	50	6210	260	110	140	5	21.0
UHB360x75	360	1100	76	82	35	6207	320	78	62	5	17.5
UHB360x90	360	1400	89	102	35	6207	320	96	82	5	19.0
UHB410x75	410	1300	76	89	40	6208	360	112	69	5	27.0
UHB410x100 ^{#8}	410	2000	102	133	40	6208	360	118	113	5	31.0
UHB410x100 ^{#10}	410	2000	102	133	50	6210	360	132	113	5	34.3
UHB410x130	410	2400	127	133	50	6210	356	128	113	5	41.0
UHB460x100	460	2200	102	133	50	6210	410	130	113	5	48.0
UHB460x130	460	2700	127	133	60	6212	407	150	113	5	54.0
UHB500x75	500	1800	76	95	35	6207	432	111	75	5	26.0
UHB500x100	500	2600	102	133	50	6210	432	127	113	5	41.0
UHB500x130	500	3500	127	133	50	6210	432	129	113	5	46.0
UHB500x150	500	4500	150	160	50	6210	432	133	140	5	58.0

※180x75につきましては金具付の場合軸径は20φになります。

※250x100、300x100につきましては金具付の場合軸径は30φになります。