

SKY-2S型 $\phi 150$ 200

自在車	固定車	
プレート式	ねじ込み式	差し込み式
三価ユニクロ仕上	クロームメッキ仕上	
シングルベアリング	ダブルベアリング	
シングルストッパー	ダブルストッパー	




SKY-2S200AW (AR) Gr




AW WF (AR) WF (Gr) UWF UWF/INJ

・図面

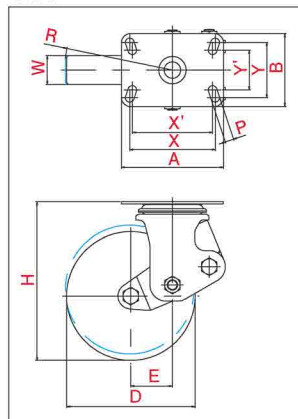

※写真は代表的な製品イメージです。

・取付方法〔プレート式〕

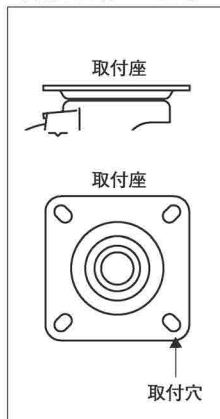

・主な使用例



品番	車輪	車輪径 D (mm)	車幅 W (mm)	取付高 H (mm)	取付座 A×B (mm)	取付寸法 X×Y (X'×Y') (mm)	穴径 P (mm)	偏心 E (mm)	旋回半径 R (mm)	基準荷重 [daN (kgf)]
SKY-2S150AW-A-1		150	42	193[~183]	159×114	133×86 (125×62)	13.5	50[~54]	126[~131]	100(102.0)
SKY-2S150AW-A-2										200(204.0)
SKY-2S200AW-A-1		200	45	246[~236]	159×114	133×86 (125×62)	13.5	65[~67]	166[~168]	100(102.0)
SKY-2S200AW-A-2										200(204.0)
SKY-2S200AW-B-1					144×144	120×120 (105×105)	11.5			100(102.0)
SKY-2S200AW-B-2										200(204.0)
SKY-2S150WF (AR) -A-1		150	40	193[~183]	159×114	133×86 (125×62)	13.5	50[~54]	126[~131]	100(102.0)
SKY-2S150WF (AR) -A-2										200(204.0)
SKY-2S200WF (AR) -A-1		200	43	246[~236]	159×114	133×86 (125×62)	13.5	65[~67]	166[~168]	100(102.0)
SKY-2S200WF (AR) -A-2										200(204.0)
SKY-2S200WF (AR) -B-1					144×144	120×120 (105×105)	11.5			100(102.0)
SKY-2S200WF (AR) -B-2										200(204.0)
SKY-2S150WF (Gr) -A-1		150	40	193[~183]	159×114	133×86 (125×62)	13.5	50[~54]	126[~131]	100(102.0)
SKY-2S150WF (Gr) -A-2										200(204.0)
SKY-2S200WF (Gr) -A-1		200	43	246[~236]	159×114	133×86 (125×62)	13.5	65[~67]	166[~168]	100(102.0)
SKY-2S200WF (Gr) -A-2										200(204.0)
SKY-2S200WF (Gr) -B-1					144×144	120×120 (105×105)	11.5			100(102.0)
SKY-2S200WF (Gr) -B-2										200(204.0)
SKY-2S150AW (AR) Gr-A-1		150	42	193[~183]	159×114	133×86 (125×62)	13.5	50[~54]	126[~131]	100(102.0)
SKY-2S150AW (AR) Gr-A-2										200(204.0)
SKY-2S200AW (AR) Gr-A-1		200	45	246[~236]	159×114	133×86 (125×62)	13.5	65[~67]	166[~168]	100(102.0)
SKY-2S200AW (AR) Gr-A-2										200(204.0)
SKY-2S200AW (AR) Gr-B-1					144×144	120×120 (105×105)	11.5			100(102.0)
SKY-2S200AW (AR) Gr-B-2										200(204.0)
SKY-2S150UWF-A-1		150	38	193[~183]	159×114	133×86 (125×62)	13.5	50[~54]	126[~131]	100(102.0)
SKY-2S150UWF-A-2										200(204.0)
SKY-2S200UWF-A-1		200	42	246[~236]	159×114	133×86 (125×62)	13.5	65[~67]	166[~168]	100(102.0)
SKY-2S200UWF-A-2										200(204.0)
SKY-2S200UWF-B-1					144×144	120×120 (105×105)	11.5			100(102.0)
SKY-2S200UWF-B-2										200(204.0)
SKY-2S150UWF/INJ-A-1		150	38	193[~183]	159×114	133×86 (125×62)	13.5	50[~54]	126[~131]	100(102.0)
SKY-2S150UWF/INJ-A-2										200(204.0)
SKY-2S200UWF/INJ-A-1		200	42	246[~236]	159×114	133×86 (125×62)	13.5	65[~67]	166[~168]	100(102.0)
SKY-2S200UWF/INJ-A-2										200(204.0)
SKY-2S200UWF/INJ-B-1					144×144	120×120 (105×105)	11.5			100(102.0)
SKY-2S200UWF/INJ-B-2										200(204.0)

※[]内の数値は荷重限度時の値