


■ 超硬ボールエンドミル 4枚刃



GM-4B

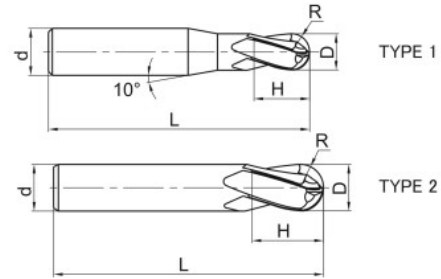

型式	基本寸法(mm)					刃数 Z	TYPE	在庫
	D	R	d	H	L			
GM-4B-R1.5	3.0	1.5	6	6	50	4	图一	●
GM-4B-R2.0	4.0	2.0	6	8	50	4	图一	△
GM-4B-R2.5	5.0	2.5	6	10	50	4	图一	●
GM-4B-R3.0	6.0	3.0	6	12	50	4	图二	△
GM-4B-R4.0	8.0	4.0	8	16	60	4	图二	●
GM-4B-R5.0	10.0	5.0	10	20	75	4	图二	△
GM-4B-R6.0	12.0	6.0	12	24	75	4	图二	●
GM-4B-R7.0	14.0	7.0	14	28	75	4	图二	●
GM-4B-R8.0	16.0	8.0	16	32	100	4	图二	●
GM-4B-R9.0	18.0	9.0	18	36	100	4	图二	●
GM-4B-R10.0	20.0	10.0	20	40	100	4	图二	●

● 国内在庫 △ 取り寄せ

汎用加工
GMシリーズ

■ 適用被削材

		被削材									
炭素鋼	合金鋼	プリハードン鋼 / 焼入鋼				ステンレス	鋳鉄 ダクタイル鋳鉄	銅合金	アルミ合金	チタン合金	耐熱合金
		~40HRC	~50HRC	~55HRC	~68HRC						
○	○	○	○		○	○					



切削条件 P41