


旋削工具

◇菱形55°

DN□□ (ネガティブ)

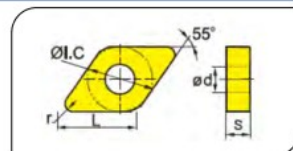

型式	寸法					ブレード	用途	P 鋼		M ステンレス			K 鋳物	
	L	LC	S	d	r			YBC152	YBC252	YBM251	YBG203	YBG205	YBD152	YBD252
DNMG 110408	11.6	9.525	4.76	3.81	0.8	DF	仕上							
						DM	中		●					
						PM	断続							
DNMG 110412	11.8	9.525	4.76	3.81	1.2	DF	仕上							
						DM	中							
						PM	断続							
DNMG 150404	15.5	12.7	4.76	5.16	0.4	DF	仕上	●	●					
						DM	中	●	●					●
						EM	中			●	●			
						PM	断続						●	
DNMG 150408	15.5	12.7	4.76	5.16	0.8	DF	仕上	●	●					
						DM	中	●	●					
						EM	中			●	●			
						PM	断続	●	●				●	●
DNMG 150412	15.5	12.7	4.76	5.16	1.2	DF	仕上	●	●					
						DM	中	●	●					
						EM	中			●				
						PM	断続		●				●	
DNMG 150608	15.5	12.7	6.35	5.16	0.8	DF	仕上	●	●					
						DM	中	●	●					
						EM	中			●				
						PM	断続	●	●				●	●
DNMG 150612	15.5	12.7	6.35	5.16	1.2	DF	仕上							
						DM	中							●
						EM	中							
						PM	断続							

PDJNR/L
Kr:93°

型式	在庫		基本寸法(mm)							ボルト	シム	レンチ	レバーピン	止めピン
	R	L	a	b	L	h	s	e						
PDJNR/L	2525M15		25	25	150	25	32	35	LEM8x21	D15AP	WH30L	L4B	SP4	