


旋削工具

◇三角形

TN□□ (ネガティブ)

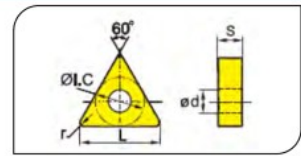

型式	寸法					ブレード	用途	P 鋼		M ステンレス		K 鋳物			
	L	LC	S	d	r			YBC152	YBC252	YBM251	YBG203	YBG205	YBD152	YBD252	
TNMG 160404	16.5	9.525	4.76	3.81	0.4	DF	仕上	●	●						
						DM	中	●	●	●		●	●		
						EM	中					●			
						PM	断続								
						全周	中~粗								
TNMG 160408	16.5	9.525	4.76	3.81	0.8	DF	仕上		●						
						DM	中	●	●					●	
						EM	中					●			
						PM	断続		●				●	●	
						全周	中~粗								
TNMG 160412	16.5	9.525	4.76	3.81	1.2	DF	仕上								
						DM	中	●	●				●		
						EM	中								
						PM	断続							●	●
						全周	中~粗								
TNMG 220408	22	12.7	4.76	5.16	1.8	DR	粗								
						HDR	粗~重								

MTJNR/L
Kr:93°

型式	在庫		基本寸法(mm)						ボルト	シム	レンチ	レバーピン	止めピン
	R	L	a	b	L	h	s	e					
MTJNR/L			20	20	125	20	25	32	DM6x25	T16BM	WH20L WH30L	C1RD	TM5x13
			25	25	150	25	32	32	DM6x30				
			32	25	170	32	32	32					