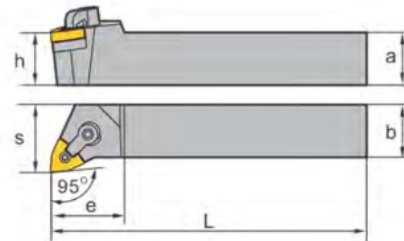


WN□□ (ネガティブ)

型式	寸法					ブレーカ	用途	P 鋼		M ステンレス			K 鋳物	
	L	LC	S	d	r			YBC152	YBC252	YBM251	YBG203	YBG205	YBD152	YBD252
WNMG 080404	8.7	12.7	4.76	5.16	0.4	DF	仕上							
						DM	中		●					
						EM	中							
						PM	断続							
WNMG 080408	8.7	12.7	4.76	5.16	0.8	DF	仕上	●	●					
						DM	中	●	●				●	●
						EM	中					●		
						PM	断続		●				●	●
WNMG 080412	8.7	12.7	4.76	5.16	1.2	DF	仕上							
						DM	中	●	●					
						EM	中				●	●		
						PM	断続		●				●	●

MWLNR/L
Kr:95°

型式		在庫		基本寸法(mm)						ボルト	シム	レンチ	レバーピン	止めピン
		R	L	a	b	L	h	s	e					
MWLNR/L	2020K06			20	20	125	20	25	30	DM6x25	W06BM	WH20L WH30L	C1RD	TM5x13
	2525M06			25	25	150	25	32	30	DM6x30				
	2020K08			20	20	125	20	25	30	DM6x25	W08BM	WH30L		TM6x17
	2525M08			25	25	150	25	32	35	DM6x30				
	3525P08			32	25	170	32	32	35					
	3232P08			32	32	170	32	40	35					